

# SERIES 77 Autoshrink™ D Cold-Action Shrink Boots and Tubing

## 777-004 Straight Wall Tubing




Straight wall tubing provides a quick, reliable method of repairing the outer jacket of Duralectric™ cables while providing mechanical and environmental protection from damage and debris. Autoshrink™ D Tubing is RoHS compliant, halogen free, and highly resistant to sunlight and ozone damage. Boots are water-tight when installed with 779-005 adhesive, sold separately. Choose tube based on wire bundle diameter. Service temperature range is -65°C to 225°C. 10 colors available.

How to Order					
Sample Part Number	777	-004	-01	-6	-1
Product Series	777 = Autoshrink™				
Basic Part Number	-004 = Straight wall tubing, Autoshrink™ D				
Size Code	See dimensions table				
Length	In inches, 12 inches maximum				
Color Code	See color table				

### NOTES

1. Adhesive 779-005 sold separately
2. Material:
  - Tubing: Duralectric™ D

Color Code	
Code	Color
0	Black
1	Brown
2	Red
3	Orange
4	Yellow
5	Green
6	Blue
7	Violet
8	Gray
9	White

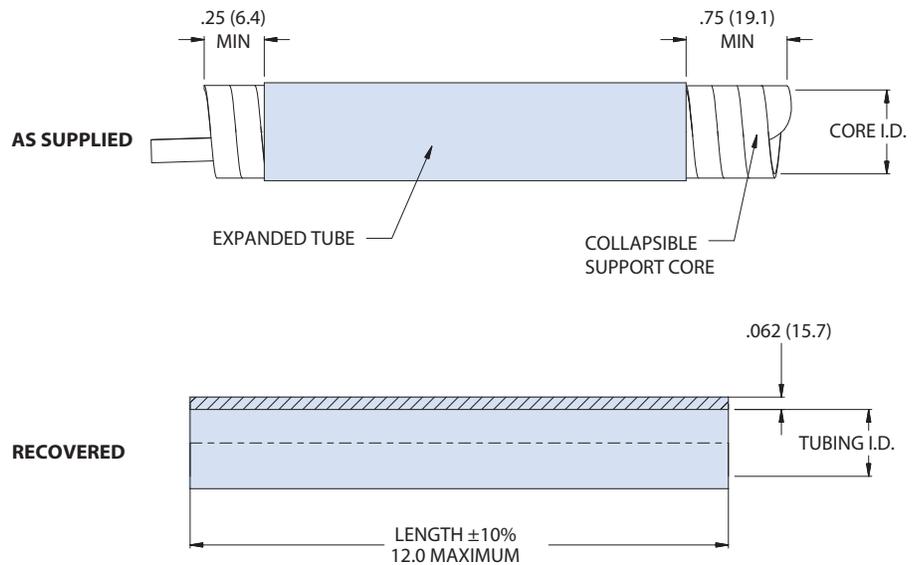

Dimensions			
Size Code	Tube I.D. After Unrestricted Shrinkage (Ref)	As Supplied Core I.D. (Ref)	Reference Wire Bundle Range Min/Max
01	.250 (6.35)	.80 (20.32)	.35 (8.89) / .65 (16.51)
02	.375 (9.52)	1.18 (29.97)	.55 (13.97) / 1.00 (25.40)
03	.625 (15.88)	2.00 (50.80)	.85 (21.59) / 1.65 (41.91)
04	.750 (19.05)	2.25 (57.15)	1.00 (25.40) / 2.00 (50.80)
05	.937 (23.80)	2.75 (69.85)	1.25 (31.75) / 2.50 (63.50)
06	1.437 (36.50)	4.00 (101.60)	2.00 (50.80) / 3.85 (97.79)