


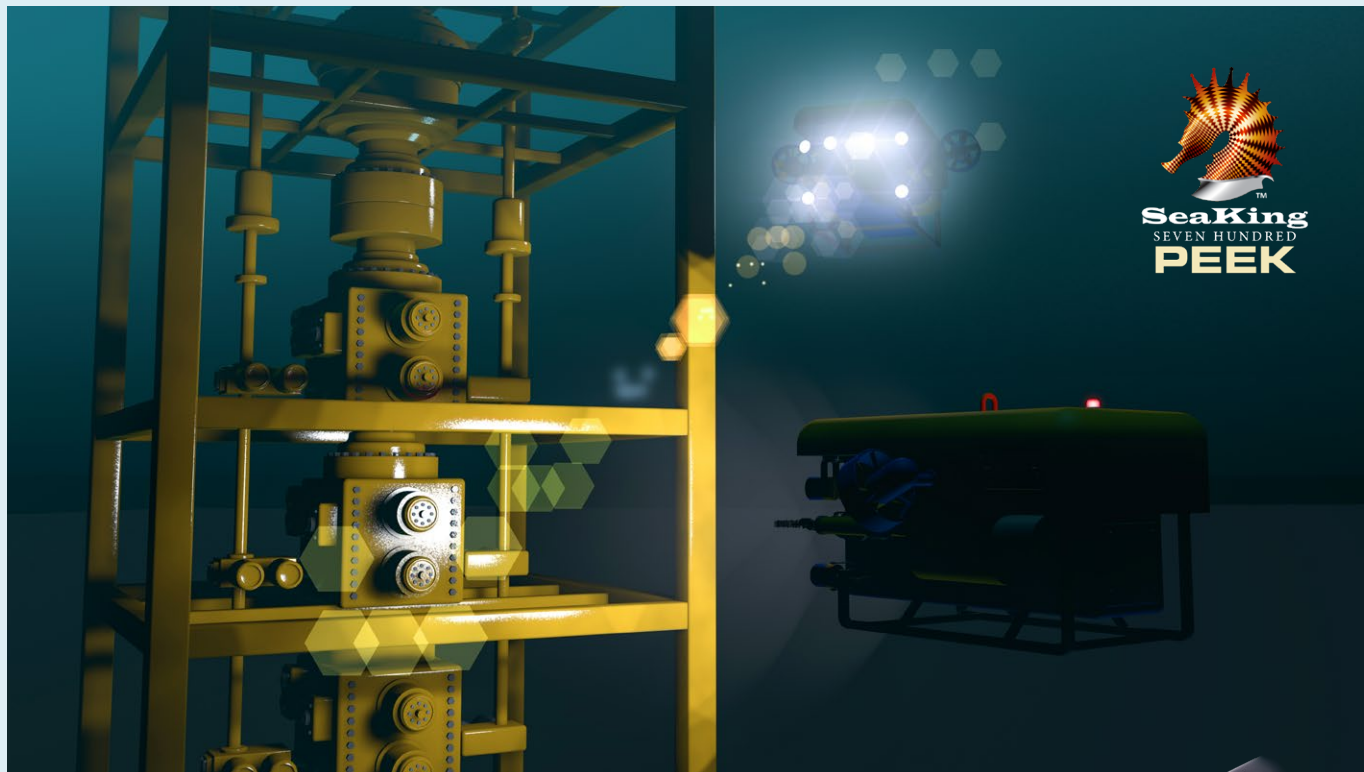

MISSION-CRITICAL UNDERWATER INTERCONNECT SOLUTIONS

Most aggressive lead times in the industry • Vertically integrated and made in the USA
Custom solutions, no minimum order quantities

Accessible and responsive engineering support • Obsessed with quality and qualification
Superior technical designs for extended durability and performance



SeaKing 700 PEEK Connectors

Glass-filled composite subsea connectors

- Superior corrosion resistance, durability, and immunity from cathodic delamination
- Same high-pressure performance as stainless steel
- Lighter weight with lower deployment costs
- Zero magnetic signature
- Galvanically compatible with all metal materials



Discrete connectors,
overmolded cables,
and PBOF assemblies
available

SERIES 700 10K PSI / 700 BAR / 7000 M

SeaKing™ High-Pressure Underwater Connectors, Cables, and PBOF Assemblies

700 Series, non-metallic PEEK connectors




700-201 CABLE CONNECTOR PLUG (CCP), PEEK



SeaKing PEEK - How To Order						
Sample Part Number	700	-201	-M12	-K	S	N
Product Series	700 = SeaKing™					
Shell Style	201 = non-metallic PEEK cable connector plug (CCP)					
Shell Size-Insert Arrangement	(see sales drawing for details)					
Shell Material	K = glass-reinforced PEEK					
Contact Style	S = socket P = pin (reverse gender)					
Polarization	A, B, C, N = normal (see sales drawing for details)					

10K PSI available in smaller shell sizes. Contact factory for details.


700-206 GLASS HERMETIC SEAL INSERT, FLANGE CONNECTOR RECEPTACLES (FCR), PEEK

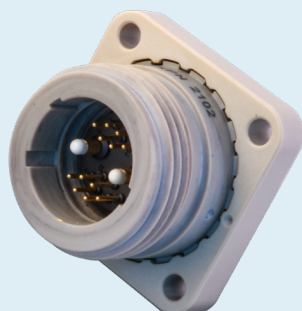

SeaKing PEEK - How To Order						
Sample Part Number	700	-206	-E4	-K	P	N
Product Series	700 = SeaKing™					
Shell Style	206 = non-metallic PEEK FCR, Glass Hermetic Seal Insert (GTMS)					
Shell Size-Insert Arrangement	(see sales drawing for details)					
Shell Material	K = glass-reinforced PEEK					
Contact Style	P = pin					
Polarization	A, B, C, N = normal (see sales drawing for details)					

10K PSI available in smaller shell sizes. Contact factory for details.

700-226 GLASS REINFORCED EPOXY INSERT, FLANGE CONNECTOR RECEPTACLES (FCR), PEEK

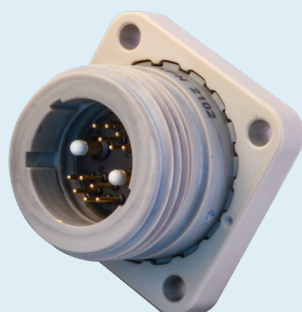

SeaKing PEEK - How To Order						
Sample Part Number	700	-226	-M12	-K	P	N
Product Series	700 = SeaKing™					
Shell Style	226 = non-metallic PEEK FCR, Glass Reinforced Epoxy Insert (GRE)					
Shell Size-Insert Arrangement	(see sales drawing for details)					
Shell Material	K = glass-reinforced PEEK					
Contact Style	P = pin S = socket (reverse gender)					
Polarization	A, B, C, N = normal (see sales drawing for details)					

10K PSI available in smaller shell sizes. Contact factory for details.

SERIES 700 10K PSI / 700 BAR / 7000 M
**SeaKing™ High-Pressure Underwater
Connectors, Cables, and PBOF Assemblies**
700 Series, non-metallic PEEK connectors



700-207 GLASS-TO-METAL SEAL INSERT, BULKHEAD CONNECTOR RECEPTACLE (BCR), PEEK



SeaKing PEEK - How To Order						
Sample Part Number	700	-207	-E4	-K	P	N
Product Series	700 = SeaKing™					
Shell Style	207 = non-metallic PEEK BCR, Glass Hermetic Seal Insert (GTMS)					
Shell Size-Insert Arrangement	(see sales drawing for details)					
Shell Material	K = glass-reinforced PEEK					
Contact Style	P = pin					
Polarization	A, B, C, N = normal (see sales drawing for details)					

700-227 GLASS REINFORCED EPOXY INSERT, BULKHEAD CONNECTOR RECEPTACLE (BCR), PEEK



SeaKing PEEK - How To Order						
Sample Part Number	700	-227	-M12	-K	P	N
Product Series	700 = SeaKing™					
Shell Style	227 = non-metallic PEEK BCR, Glass Reinforced Epoxy Insert (GRE)					
Shell Size-Insert Arrangement	(see sales drawing for details)					
Shell Material	K = glass-reinforced PEEK					
Contact Style	P = pin S = socket (reverse gender)					
Polarization	A, B, C, N = normal (see sales drawing for details)					