

# Series 31 Shrink Boot Adapters

for MIL-DTL-26482 Series I Connectors

## 310DS034 Shrink Boot Adapter, Direct Coupling




### Adapter Code **D**

This accessory fits MIL-DTL-26482 Series I connectors

### SHRINK BOOT

Optional heatshrink boot provides cable strain relief and environmental protection. Type 1 high-performance semi-rigid elastomer resists fuels and oils and withstands temperature extremes.

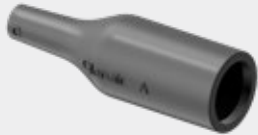

Shell Size	Shrink Boot P/N
08	<a href="#">770-003S102</a>
10	<a href="#">770-003S103</a>
12	<a href="#">770-001S103</a>
14	<a href="#">770-001S103</a>
16	<a href="#">770-001S104</a>
18	<a href="#">770-001S104</a>
20	<a href="#">770-001S106</a>
22	<a href="#">770-001S107</a>
24	<a href="#">770-001S107</a>

**Direct coupling. Low profile.** 310DS034 shrink boot adapter fits M26482 Series I connectors. Adapter has groove for lipped shrink boot. Supplied as adapter only or as kit with shrink boot. Aluminum or stainless steel.

### PART NUMBER


**310DS034 NF 14 T**

Base P/N **310DS034**

**Material/Finish**  
**M** Alum/ Electroless Nickel  
**MT** Alum/ Nickel-PTFE  
**NF** Alum/ Olive Drab Cadmium  
**ZR** Alum/ Black Zinc-Nickel  
**TZ** Alum/ Tin-Zinc  
**ZI** SST/ Passivated

Shell Size **08 10 12 14 16 18 20 22 24**

Shrink Boot *Omit if not required*  
**T** Shrink Boot included

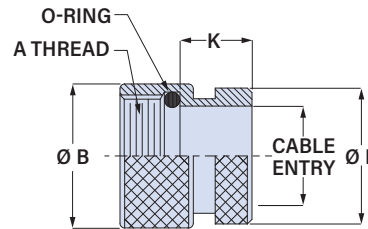

Shell Size	A		K Max		ø L Max		Cable Entry		
	Thread	ø B Max	in	mm	in	mm	Min	mm	
<b>08</b>	0.4375-28	.59	15.0	.500	12.7	.688	17.5	.250	6.4
<b>10</b>	0.5625-24	.72	18.3	.500	12.7	.803	20.4	.355	9.0
<b>12</b>	0.6875-24	.84	21.3	.500	12.7	.938	23.8	.491	12.5
<b>14</b>	0.8125-20	.97	24.6	.500	12.7	1.063	27.0	.565	14.4
<b>16</b>	0.9375-20	1.09	27.7	.500	12.7	1.238	31.4	.690	17.5
<b>18</b>	1.0625-18	1.22	31.0	.500	12.7	1.310	33.3	.769	19.5
<b>20</b>	1.1875-18	1.34	34.0	.500	12.7	1.436	36.5	.844	21.4
<b>22</b>	1.3125-18	1.47	37.3	.500	12.7	1.560	39.6	1.019	25.9
<b>24</b>	1.4375-18	1.59	40.4	.500	12.7	1.686	42.8	1.134	28.8