

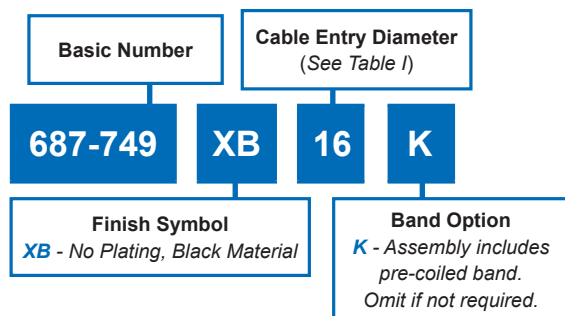


**687-749**  
**Composite AS85049/93**  
**Banding Split-Ring**

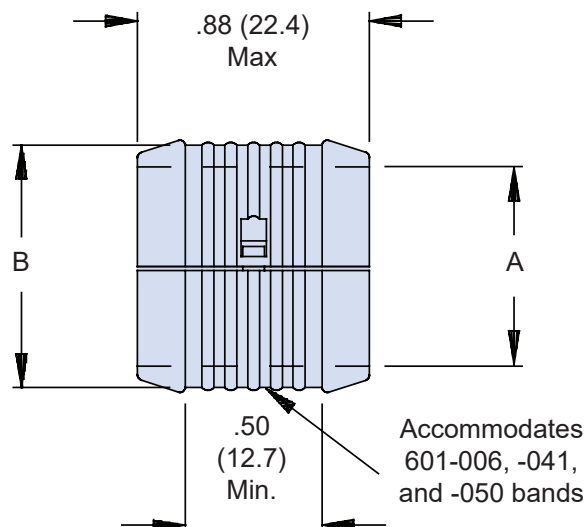

**For Use with Glenair  
 Banding Backshells  
 and Braid Socks**

**Consult Factory for  
 Information on Other  
 Split Ring Designs and  
 Part Numbers**

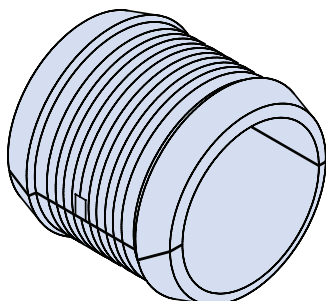

- APPLICATION NOTES**
- 687-749 supersedes and replaces 687-207 split ring.
  - Metric dimensions (mm) are in parentheses and are for reference only.

| TABLE I: DASH NUMBER |                           |                           |                            |  |
|----------------------|---------------------------|---------------------------|----------------------------|--|
| Dash No.             | A Diameter<br>± .03 (0.8) | B Diameter<br>± .03 (0.8) | Compatible<br>Glenair Band |  |
| 04                   | .25 (6.4)                 | .36 (9.1)                 | 601-006                    |  |
| 06                   | .38 (9.7)                 | .49 (12.4)                | 601-006                    |  |
| 08                   | .50 (12.7)                | .61 (15.5)                | 601-006                    |  |
| 10                   | .63 (16.0)                | .74 (18.8)                | 601-006                    |  |
| 12                   | .75 (19.1)                | .86 (21.8)                | 601-006                    |  |
| 14                   | .88 (22.4)                | .99 (25.1)                | 601-041                    |  |
| 16                   | 1.00 (25.4)               | 1.10 (27.9)               | 601-041                    |  |
| 18                   | 1.13 (28.7)               | 1.24 (31.5)               | 601-041                    |  |
| 20                   | 1.25 (31.8)               | 1.36 (34.5)               | 601-041                    |  |
| 22                   | 1.38 (35.1)               | 1.49 (37.8)               | 601-041                    |  |
| 24                   | 1.50 (38.1)               | 1.61 (40.9)               | 601-041                    |  |
| 26                   | 1.63 (41.4)               | 1.74 (44.2)               | 601-041                    |  |
| 28                   | 1.75 (44.5)               | 1.86 (47.2)               | 601-050                    |  |
| 30                   | 1.88 (47.8)               | 2.00 (50.8)               | 601-050                    |  |
| 32                   | 2.00 (50.8)               | 2.13 (54.1)               | 601-050                    |  |
| 36                   | 2.25 (57.2)               | 2.38 (60.4)               | 601-050                    |  |

**EXAMPLE  
 APPLICATION**

