

OPTIMIZED
FOR USE WITH



SeaKing
PRESSURE-RATED CABLES

MARINE MOLDED™

Industry-Standard Wet-Pluggable Rubber Molded Connectors

In-Line Mated Pair
with Locking Sleeves



Intermateable and intermountable industry- standard rubber molded connectors for ROVs and other Oil & Gas applications

Glenair Marine Molded (Series GLMC) rubber molded connectors are fabricated using only the highest-grade materials and quality controls. Prewired inline and bulkhead connectors are supplied in symmetrical layouts from two to sixteen contacts for subsea ROV, towed-array, offshore oil, and other harsh oil and gas industry applications. The industry-standard connector series is fully compatible (intermountable and intermateable) with other connector series of this type.

- Wet pluggable capability
- Up to 10,000 psi / 690 Bar (6,800m/22,500ft) mated
- 2-16 contact layouts available
- Locking sleeves - multiple colors available
- 316L stainless steel bulkhead (standard), brass and PEEK available
- 600 V (2, 3, and 4-way)
- 300 V (5, 6, 8, 10, 12, and 16-way)
- Overmolded with standard Neoprene, Nitrile, Hypalon, or Polyurethane

SERIES GLMC

Marine-Molded Connectors and Cables

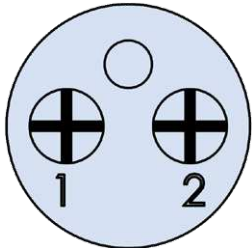
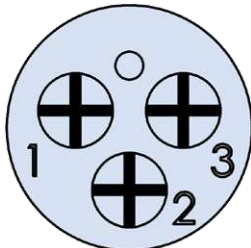
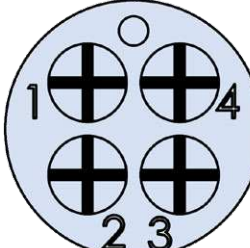
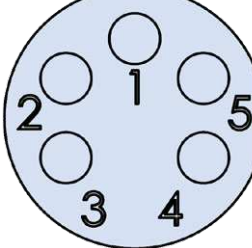
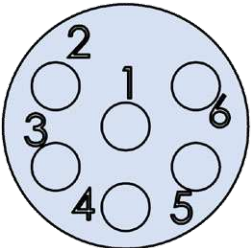
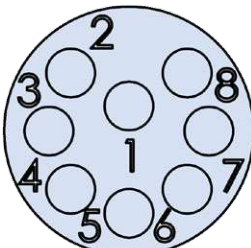
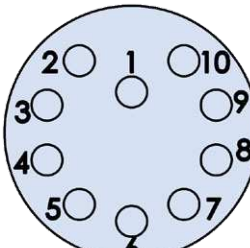
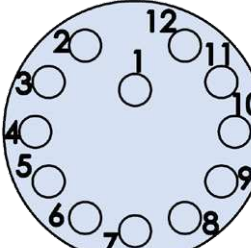
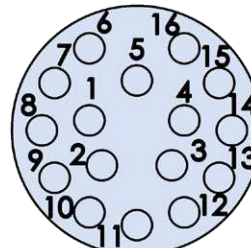


Wet-pluggable · 10K psi · intermateable and intermountable

GLMC CONNECTOR CONFIGURATIONS



INSERT ARRANGEMENTS

				
2 Way BH - 20 AWG Wires IL - 18 AWG Wires	3 Way BH - 20 AWG Wires IL - 18 AWG Wires	4 Way BH - 20 AWG Wires IL - 18 AWG Wires	5 Way BH - 22 AWG Wires IL - 20 AWG Wires	
				
6 Way BH - 22 AWG Wires IL - 20 AWG Wires	8 Way BH - 22 AWG Wires IL - 20 AWG Wires	10 Way BH - 22 AWG Wires IL - 20 AWG Wires	12 Way BH - 22 AWG Wires IL - 20 AWG Wires	16 Way BH - 22 AWG Wires IL - 20 AWG Wires

M
N
O
P
Q
R
S
T
U
V
W
X
Y
Z