


OPTIMIZED
FOR USE WITH



SeaKing
PRESSURE-RATED CABLES



**SeaKing™ 700 dry-mate
underwater connectors
and mil-qualified / MCOTS
cable assemblies**

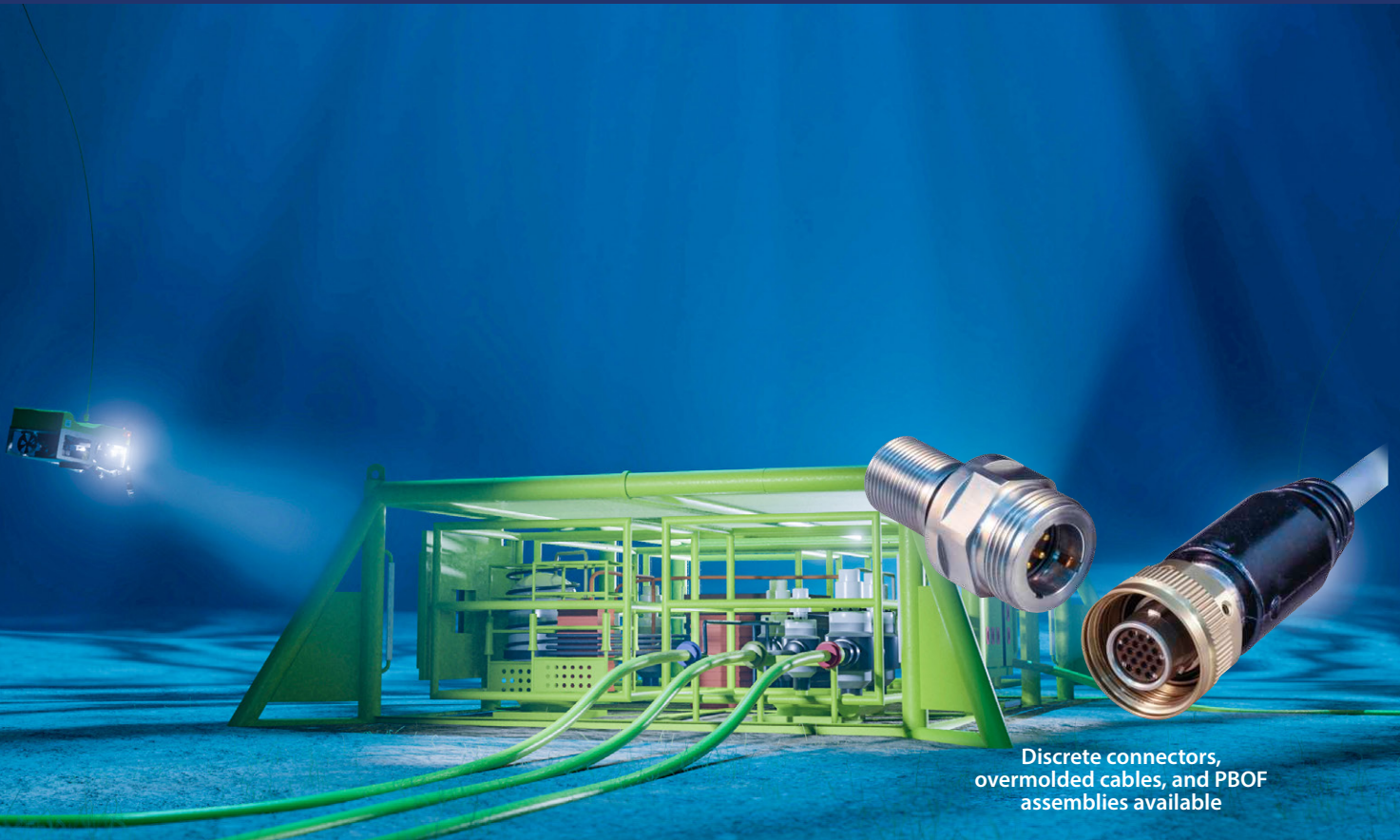

Discrete connectors,
overmolded cables, and PBOF
assemblies available

SeaKing 700 is an innovative 10K psi open-face rated underwater connector series that eliminates a broad range of mechanical design weaknesses found in many of today's high-pressure subsea connector families. From its double O-ring seals and retractable engaging nut, to its multi-keyed mating interface, the SeaKing underwater connector represents a far more reliable approach to subsea power and signal connectivity.


- High density, small form-factor connector
- Dual O-ring seals ensure high-pressure performance for every leak path
- Signal, power, RF, and optical insert arrangements
- Stainless steel or titanium with anti-galling marine bronze engaging nut or cathodic delamination-free PEEK
- Full-mate inspection ports
- Easy O-ring replacement
- Key and keyway polarization

10K PSI / 700 BAR OPEN-FACE RATING

SeaKing™ 700 High-Pressure Subsea Connectors



Electrical · optical · power · turnkey cables

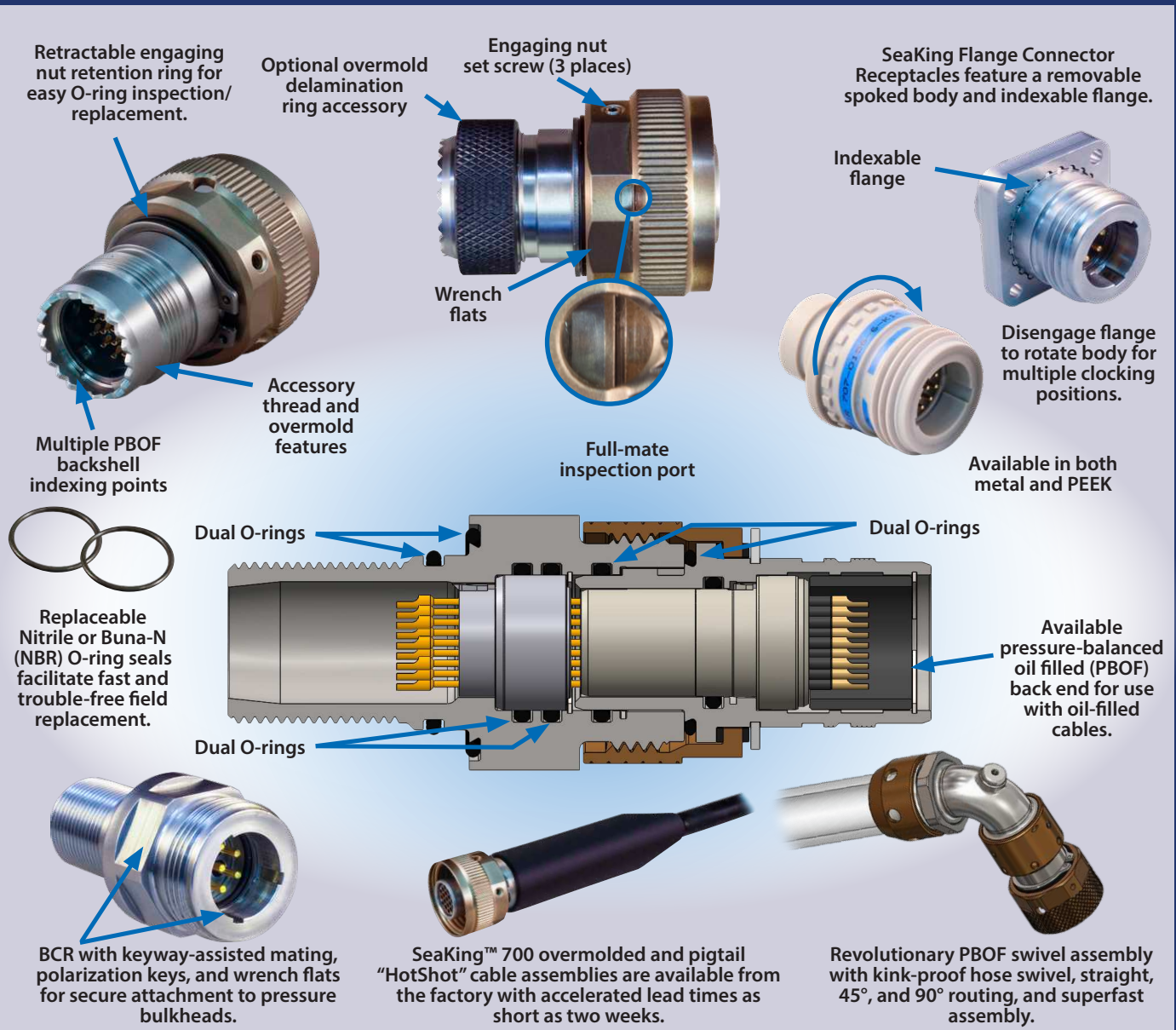

SeaKing PEEK, SeaKing Power, and SeaKing Fiber Optic Configurations

