

Protocols, Exploded Views of Type I and Type II Contacts

El Ochito® White



100BASE-T, 10GBASE-T

El Ochito® White octaxial contacts provide 10GbE in a single size #8 contact cavity (compared to two Quadrax) for 100BASE-T solutions.

El Ochito® Blue



SuperSpeed USB

Low-dielectric material. 90 ohms. El Ochito® Blue octaxial contacts provide an aerospace-grade solution for SuperSpeed USB 3.0

El Ochito® Red




HDMI, DisplayPort, SATA


Low-dielectric material. Up to 5 Gbps. 100 ohms. El Ochito® Red octaxial contacts provide an aerospace-grade solution for multi-gigabit data rates.

El Ochito® Type I Contacts

26 AWG, Non-Serviceable, Crimp Wire Shield Termination

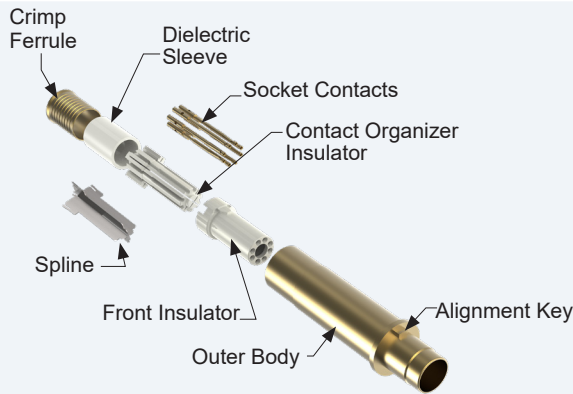


Type I Pin Contact

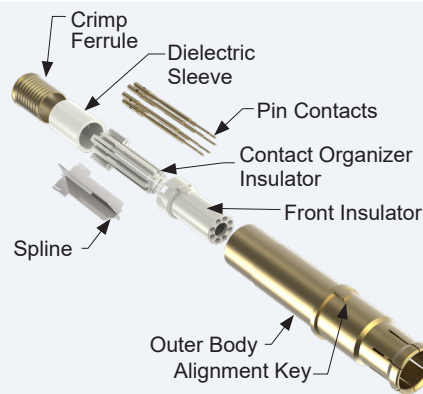


Type I Socket Contact

El Ochito® Type II Contacts

24-26 AWG, Serviceable, Threaded Wire Shield Termination, Integral Contact Release Sleeve

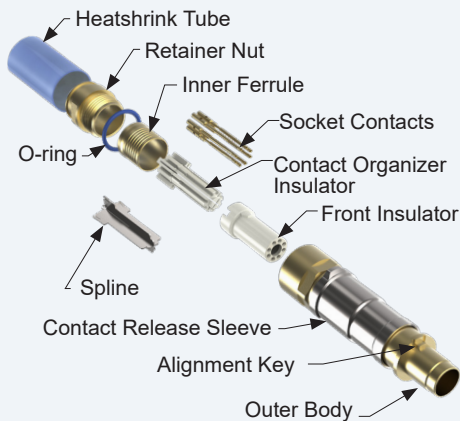

Type II Pin Contact

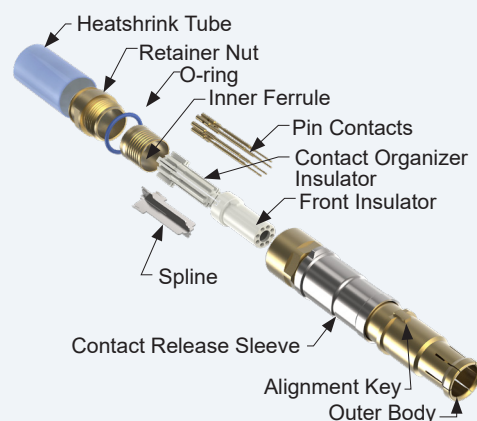

Type II Socket Contact