


Selection Guide

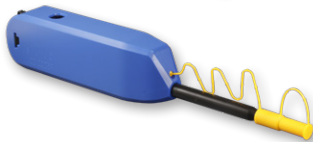

CATALOG NOTES

- Metric dimensions appear in parentheses in diagrams and tables, based on 1 inch = 25.4 mm, for reference only.
- Unless otherwise specified, the following other dimensional tolerances apply:
- .xx = ± .03 (0.8) • .xxx = ± .015 (0.4) • Angles = ± 5°

Product No.	Description	Page No.
FIBER OPTIC PREPARATION AND TERMINATION EQUIPMENT		
GFKR	Fiber Optic Cable Preparation and Termination	J-2
	Glenair Fiber Optic Termination, Testing, Cleaning and Inspection Kits	J-4
	Polishing Pucks	J-5
	Terminus and Alignment Sleeve Insertion and Extraction Tools	J-6
	Fiber Optic Terminus Insertion and Extraction Tools	J-8
FIBER OPTIC INSPECTION AND TEST EQUIPMENT		
GTK1000	Fiber Optic Testing Kit for MIL-DTL-38999 Series III Fiber Optic Connection Systems	J-11
ABC 54705	Replacement Fiber Optic Test Probe Jumper	J-13
180-043, 180-049, 180-050	Test probe calibration (zeroing) adapters	J-14
180-044 (06)	Fiber Optic Test Adapter, Plug	J-15
180-044 (07)	Fiber Optic Test Adapter, Receptacle	J-17
180-072 (06)	Fiber Optic Test Adapter, Plug	J-19
180-072 (07)	Fiber Optic Test Adapter, Receptacle	J-21
180-073 (06)	Fiber Optic Test Adapter, Plug	J-23
180-073 (07)	Fiber Optic Test Adapter, Receptacle	J-25
GTK2000	GHD Fiber Optic Connection Systems Fiber Optic Testing Kit	J-27
FO04309	GHD Fiber Optic Test Probe	J-29
FA00861	GHD Fiber Optic Test Probe	J-30
180-154, 180-173	Calibration (zeroing) Adapters	J-31
180-131	Fiber Optic Test Adapter, Plug and Receptacle	J-32
GTK3000	ARINC 801 Fiber Optic Connection Systems Testing Kit	J-34
FO04309	ARINC801 Fiber Optic Test Probe	J-36
FA00861	ARINC801 Fiber Optic Test Probe	J-37
180-154, 180-173	Calibration (zeroing) Adapters for ARINC 801 Fiber Optic Connectors	J-38
187-214	Fiber Optic Test Adapter, Plug and Receptacle for ARINC 801 Fiber Optic Connectors	J-39
GTK4000	Fiber Optic Testing Kit for NGCON Fiber Optic Connection Systems	J-41
FO04309	NGCON Fiber Optic Test Probe	J-43
FA00861	NGCON Fiber Optic Test Probe	J-44
180-173, 180-154	Test Probe Calibration Adapters for MIL-PRF-64266 Fiber Optic Connectors	J-45
180-134	Fiber Optic Test Adapter, Plug and Receptacle For NGCON	J-46
180-102	Fiber Optic Probe Adapter, Plug and Receptacle for NGCON	J-48
FO1006	Fiber Optic Patch Cord	J-49
FO1007	Fiber Optic Patch Cord	J-50
FIBER OPTIC CLEANING AND TROUBLESHOOTING EQUIPMENT		
	Fiber Optic Cleaning and Troubleshooting	J-51
	Fiber Optic Cleaning and Troubleshooting Process Flow	J-52
GBS1000/GBS1001	Portable Video Bore Scope Inspection System	J-53
GCLT	Dry Action Cleaning Tools	J-55
187-021/187-024/187-045	Fiber Optic Cleaning Swabs	J-56
GENERAL-PURPOSE TOOLS		
601-100/600-058	Band-Master™ ATS Termination System Standard Banding Tools	J-57
601-101/600-061	Band-Master™ ATS Termination System Micro Banding Tools	J-59
	EMI Shield Termination Instructions	J-61
	Glenair Fiber Optic Custom Tooling Request	J-62