

244-002

MIL-DTL-38999 Series III Type TVS Connector Wall Mount Receptacle with RJ45 Jack To Rear Solder Cup or PC Tail Termination and Standoffs



TVS Connectors



Materials and Finishes¹

NF	Cadmium olive drab
ME	Electroless nickel
MT	Nickel PTFE

NOTES


- See Section A for alternate key positions, panel cutout dimensions and complete finish options

All external dimensions, features, etc. compliant with D38999/20, /24, &/26. Consult factory for additional information.

How to Order


Sample Part Number	244-002	NF	19	P	G	N	1
Basic Number	244-002						
Finish ¹	See Material & Finish Table						
Shell Size ¹	17 or 19						
Termination	P = PC tail S = Solder cup						
Insert-to-Shell Grounding	G = Shielded and grounded to shell						
Alternate Key Position ¹	Per MIL-DTL-38999 A, B, C, D, E, N = Normal						
RJ45 Orientation	1, 2, 3, or 4						

RJ45 ORIENTATION CODE AND PCB LAYOUT (PCB LAYOUT FOR PC TAIL VERSION)

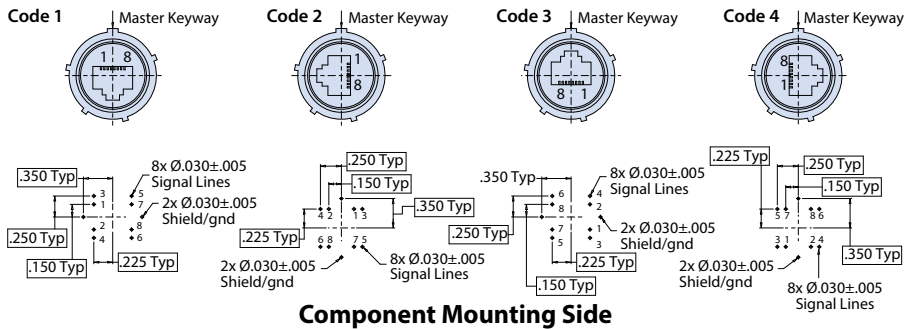

Jam Nut Dimensions

Shell Size	A Thread	B Sq.		C Bsc		Ø D Min.		E Bsc	
		in	mm	in	mm	in	mm	in	mm
17	1.1875-1P-.3L-TS-2A	1.323 1.299	33.60 32.99	1.062	26.97	1.219	30.96	1.062	26.97
19	1.2500-1P-.3L-TS-2A	1.449 1.425	36.80 36.195	1.156	29.36	1.297	32.94	1.156	29.36

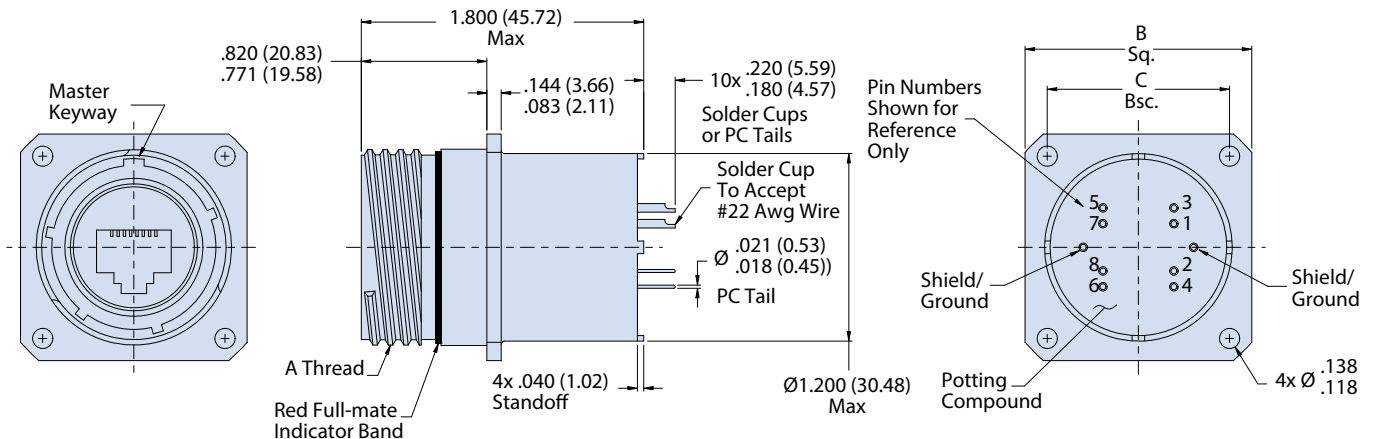

Dimensions in inches (millimeters) and are subject to change without notice.

© 2013 Glenair, Inc.

U.S. CAGE Code 06324

Printed in U.S.A.

GLENAIR, INC. • 1211 AIR WAY • GLENDALE, CA 91201-2497 • 818-247-6000 • FAX 818-500-9912
www.glenair.com J-9 E-Mail: sales@glenair.com