


Transient Voltage Supression (TVS) Connectors




Product Selection Guide

242-383A
Page J-2

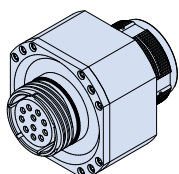


MIL-DTL-38999 Series III Type TVS Adapter

242-383P
Page J-4

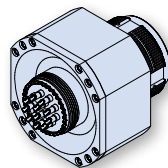

MIL-DTL-38999 Series III Type TVS Plug
with Solder Cup Contacts

242-383S
Page J-6

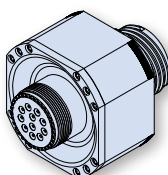

MIL-DTL-38999 Series III Type TVS Jam Nut Receptacle
with Crimp Contacts

244-001
Page J-8



MIL-DTL-38999 Series III Type TVS Jam Nut Receptacle with Front
RJ45 Jack to Rear Solder Cup or PC Tail Termination

244-002
Page J-9



SuperSeal™
MIL-DTL-38999 Series III Type TVS Jam Nut Receptacle with Front
RJ45 Jack to Rear Solder Cup or PC Tail Termination and Standoffs

244-003
Page J-10



SuperSeal™
MIL-DTL-38999 Series III Type TVS Jam Nut Receptacle with RJ45
Jack to Rear Solder Cup or PC Tail Termination and Standoffs

244-004
Page J-11



SuperSeal™
MIL-DTL-38999 Series III Type TVS Wall Mount Receptacle with
RJ45 Jack to Rear Solder Cup or PC Tail Termination and Standoffs

Dimensions in inches (millimeters) and are subject to change without notice.