

107-521 Stainless Steel Wire Rope, M24749 Type I style with lug hole and length options

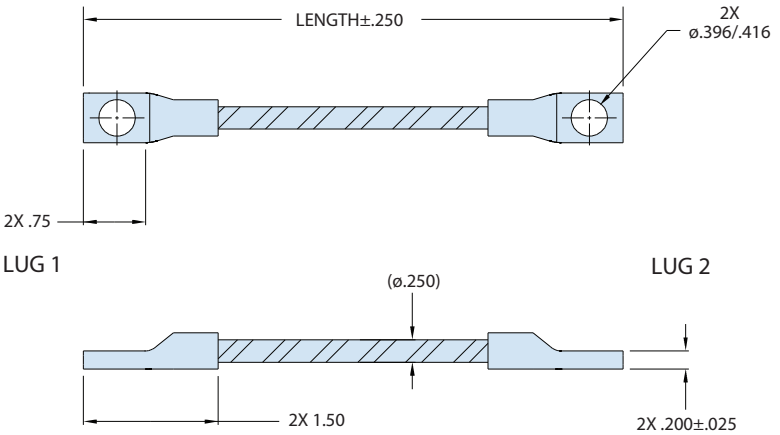
HOW TO ORDER			
Sample Part Number	107-521	-N	-L
Product Series	Nonstandard wire rope ground strap		
Standard Size Code	See Size Codes Table N = For Nonstandard Sizes		
Length	Only for Nonstandard		

GROUND STRAP FEATURES

- Meets the rigorous specifications of MIL-DTL-24749 Rev. C type I with length and lug configuration options beyond standard mil-spec straps.
- Materials in accordance with MIL-DTL-24749 Rev. C or equivalent, unless specified.
- Lug holes in accordance with AS7928.
- Bosses and bolts ordered separately, see 107-505.

MATERIAL/FINISH

- Lugs: 316L stainless steel/ passivate per AMS2700.
- Rope: 316 stainless steel, .250 inch dia., annealed / passivate per AMS2700.

SIZE CODES		
		
Standard Size Code	Length	Hole Diameter
A	6.0	13/32 (0.406)
B	12.0	13/32 (0.406)
C	18.0	13/32 (0.406)