


## Flat CRES 316L/Nickel 200 Braid with Mounting Holes Mil-qualified for shipboard electrical bonding applications

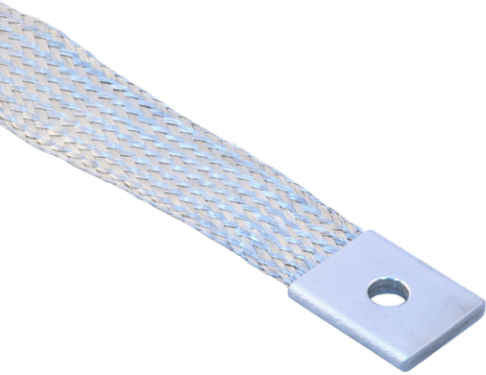

HOW TO ORDER					
Sample Part Number	M24749	-IV	-N	-L	-H
Product Series	MIL-DTL-24749 Type IV Ground Strap				
Bond Strap Type	IV = Flat CRES 316L/Nickel 200 Braid				
Standard Size Code	See Table N = For Nonstandard Sizes				
Length	Only for Nonstandard				
Hole Diameter	Only for Nonstandard .281 or .406				

### GROUND STRAP FEATURES

- Meets the rigorous specifications of MIL-DTL-24749 Type IV grounding straps.
- Intended use for bonding items in non-weather exposed areas where corrosion is a concern. Type IV is also for use below deck across sound dampening devices, in grounding or bonding of 1/4-inch stud-mounted equipment, or in grounding or bonding of portable electrical equipment.
- For more options see Glenair Part Number 107-500 or 107-504.

### MATERIAL/FINISH

- Lugs: 316L stainless steel per ASTM A269/N.A.
- Braid: 36 AWG, 316L stainless steel (50%)-200 nickel (50%)/N.A.

