


.062" PITCH COMPLIANT PIN HD Stacker™

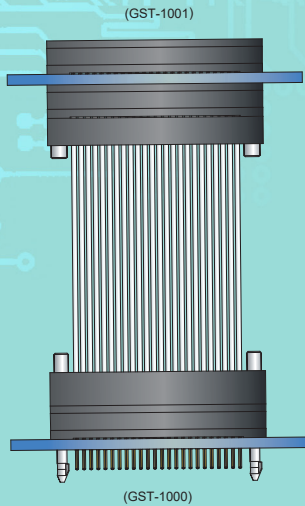


GST-1006 pre-wired cable assembly, GST-1000 to GST-1001

MATES WITH GST



How to Order GST-1006 HD Stacker Connectors	
Sample Part Number	GST-1006 -120 -4 K 7 -18 T1F1
Series	GST-1006 = Glenair HDS GST-1000 to GST-1001
Number of Contacts	40, 80, 120, 160, 200, 240
Wire Gauge	4 = #24 6 = #26 8 = #28
Wire Type	K = M22759/11 600 VRMS Teflon (TFE) J = M22759/33 600 VRMS Modified Cross-Linked Tefzel (ETFE) E = NEMA HP3-EB 600 VRMS Type E M16878/4 (TFE)
Wire Color	1 = White 2 = Yellow 7 = Ten-Color Repeating
Wire Length	Length in Inches ("-18" Specifies 18 Inches.) 4" Minimum.
Hardware T (GST-1000 end) F (GST-1001 end)	<div style="display: flex; justify-content: space-around;"> <div style="text-align: center;">1 PIN 1 R R</div> <div style="text-align: center;">2 PIN 1 R L</div> <div style="text-align: center;">3 PIN 1 L L</div> <div style="text-align: center;">4 PIN 1 L R</div> </div>

- High-density layouts from 40 to 240 contacts
- Polarized insulators
- Keyed guide pin hardware for mis-mate protection
- Mil-qualified hookup wire in white, yellow, and ten-color repeat

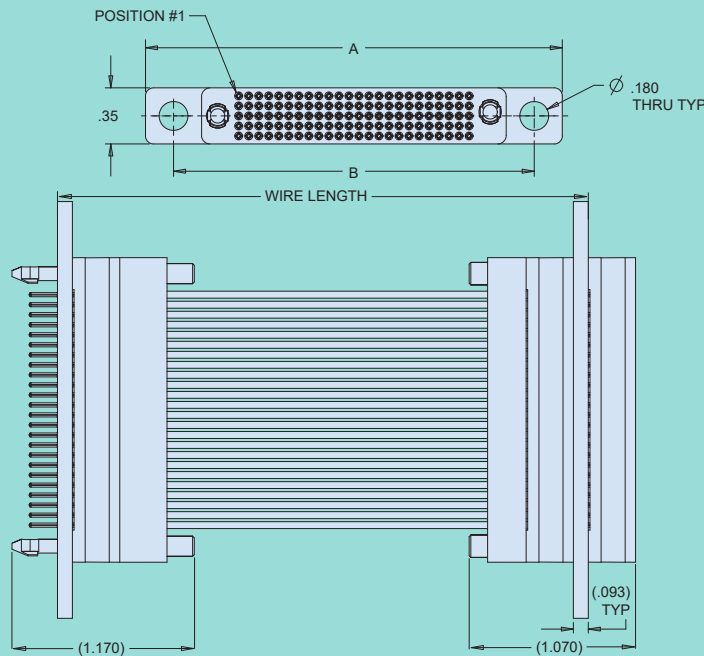

Number of Contacts	A		B	
	in	mm	in	mm
40	1.60	40.64	1.25	31.75
80	2.10	53.34	1.75	44.45
120	2.60	66.04	2.25	57.15
160	3.10	78.74	2.75	69.85
200	3.60	91.44	3.25	82.55
240	4.10	104.14	3.75	95.25