


.062" PITCH COMPLIANT PIN

HD Stacker™

GSTT-PF PC-tail (flex) connector Top-of-stack




MATES WITH GSTB

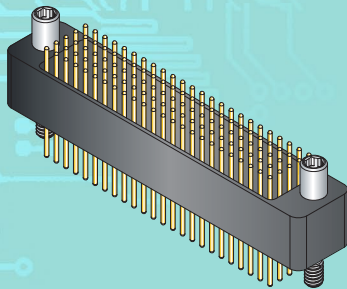

- Innovative Chevron Contact System (CCS)
- High-density layouts from 40 to 300 contacts
- Polarized insulators
- Keyed guide pin hardware for mis-mate protection
- Turnkey PC-tail flex jumpers available from Glenair, consult factory.





All Glenair HD Stacker™ connectors are equipped with our innovative .062" pitch high-density Chevron Contact System (CCS). Special non-orthogonal socket tines enable both higher density layouts as well as improved signal integrity. The GSTT-PF is equipped with pin contacts and PC tails for termination to flex

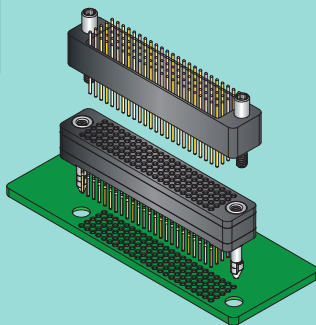

The GSTT-PF is a top-of-stack connector for termination to flex. Shown: GSTT-PF stack-mating with GSTB.

How to Order GSTT-PF HD Stacker Connectors						
Sample Part Number	GSTT	-120	P	F	-.080	M
Series	GSTT = PC Tail Top Stacker (for flex termination)					
Number of Contacts	40, 80, 120, 160, 200, 240, 300					
Contact Type	P = Pin					
Termination Type	F = PC Tail (for flex termination)					
PC Tail Length	.080, .110, .140, .172, .190, .250					
Hardware	M = #2-56 Hex Head Jackscrew					

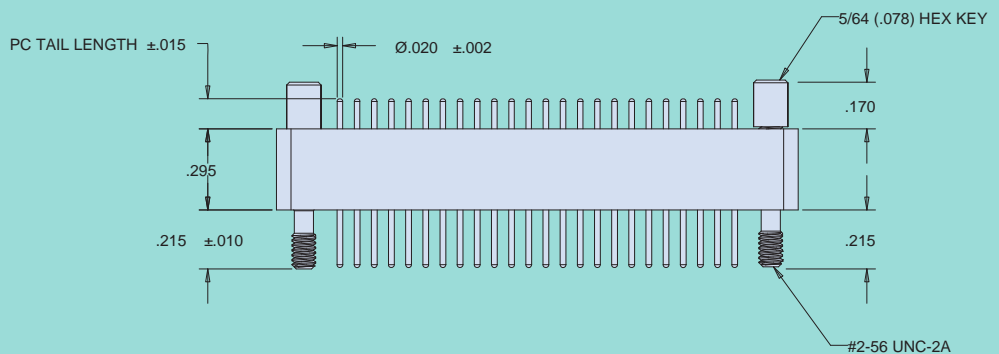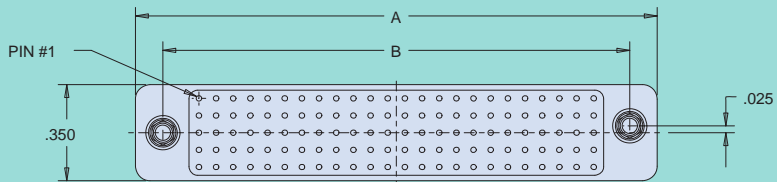

Number of Contacts	A		B	
	in	mm	in	mm
40	0.90	22.86	0.70	17.78
80	1.40	35.56	1.20	30.48
120	1.90	48.26	1.70	43.18
160	2.40	60.96	2.20	55.88
200	2.90	73.66	2.70	68.58
240	3.40	86.36	3.20	81.28
300	4.15	105.41	3.95	100.33

.062" PITCH COMPLIANT PIN

HD Stacker™

GSTT-PF PC-tail (flex) connector

Top-of-stack



FLEX LAYOUTS (COMPONENT SIDE)

