

IPT 3181-C and IPT 3181-CF Protective Receptacle Covers



IPT Bayonet Lock
Connector
Accessories

MIL-DTL-26482 Series I
Accessory

Basic Part Number
and Shell Size

Lanyard Style
C - Chain
CF - Nylon Cord
Z1C - Nylon Cord


Finish Options
See Table II

IPT

3181-10

C

F11

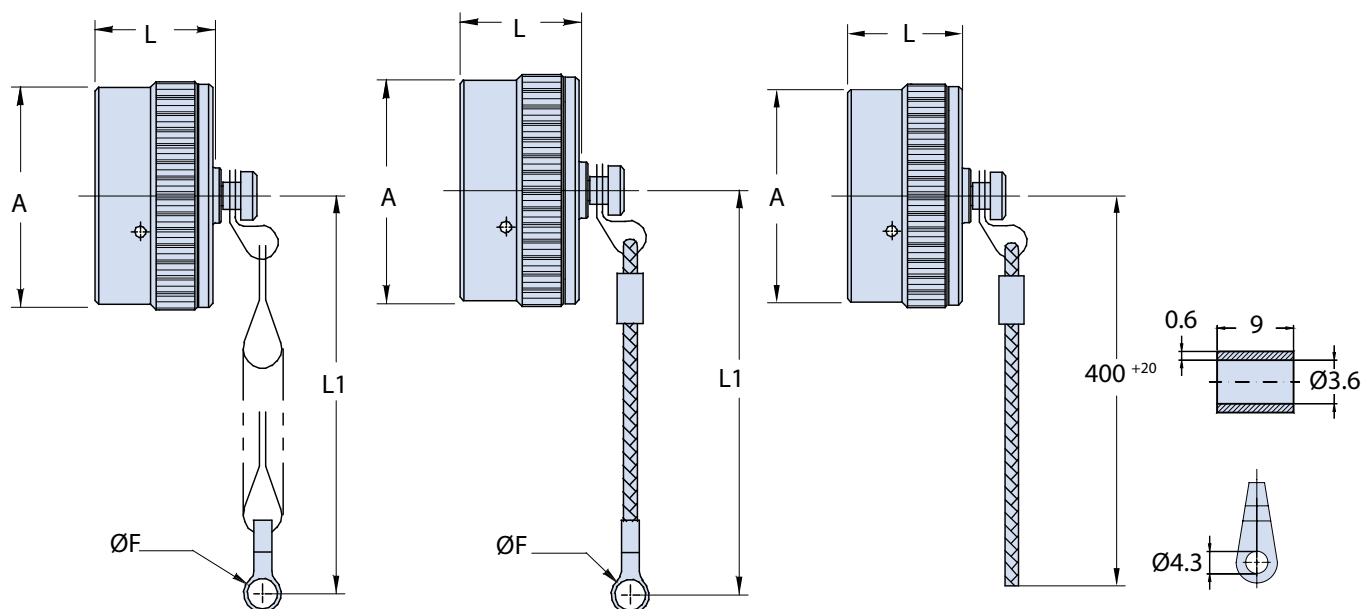

Example: IPT3181-18C
(Stainless Steel Chain)

Example: IPT3181-18CF
(Nylon Cord)

Example: IPT3181-18Z1C
(Nylon Cord with loose terminal link and sleeve)

TABLE I: DIMENSIONS

GLENAIR P/N	Shell size	A Max.	ØF +0.2 -0	L Max.	L1 min.
IPT3181- 8C	8	17.95	4.3	14.30	76.2
IPT3181-10C	10	21.05	4.3	14.30	76.2
IPT3181-12C	12	25.40	4.3	14.30	88.9
IPT3181-14C	14	26.60	4.3	14.30	88.9
IPT3181-16C	16	31.80	4.3	14.30	88.9
IPT3181-18C	18	35.00	4.3	14.30	88.9
IPT3181-20C	20	38.00	4.3	14.30	101.6
IPT3181-22C	22	41.25	4.3	14.30	101.6
IPT3181-24C	24	44.40	4.3	15.30	101.6

Application Notes

Metal protective cover for receptacle connectors with stainless steel chain or nylon cord.

TABLE II: MODIFICATION CODES

Shell Finish (Omit for Standard Cad/Olive Drab Finish)
F6 - Black Electrodeposited Paint (RoHs)
F7 - Black Zinc Nickel (RoHs)
F11 - Electroless Nickel (RoHs)
MB - Marine Bronze (RoHs)