

IPT 3181-N and IPT 3181-NF Protective Jam Nut Receptacle Covers

MIL-DTL-26482 Series I
Accessory

Lanyard Style
N - Chain
NF - Nylon Cord

IPT


3181-10

N


F11

**Basic Part Number
and Shell Size**

Finish Options
See Table II

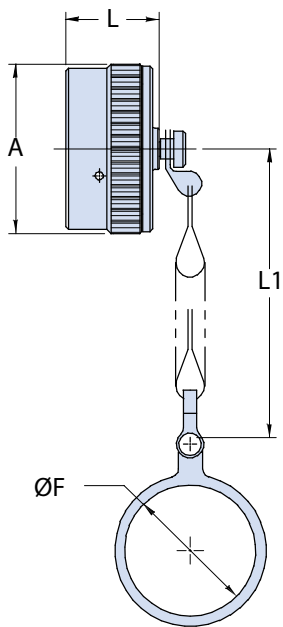

Example: IPT3181-18N
(Stainless Steel Chain)

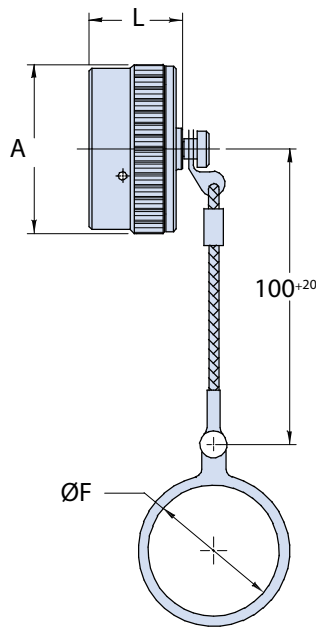

Example: IPT3181-18NF
(Nylon Cord)

TABLE I: DIMENSIONS

GLENAIR P/N	Shell size	A Max.	ØF +0.2 -0.1	L Max.	L1 min.
IPT3181- 8N	8	17.95	14.70	14.30	76.2
IPT3181-10N	10	21.05	17.85	14.30	76.2
IPT3181-12N	12	25.40	22.65	14.30	88.9
IPT3181-14N	14	26.60	25.80	14.30	88.9
IPT3181-16N	16	31.80	29.00	14.30	88.9
IPT3181-18N	18	35.00	32.15	14.30	88.9
IPT3181-20N	20	38.00	35.35	14.30	101.6
IPT3181-22N	22	41.25	38.50	14.30	101.6
IPT3181-24N	24	44.40	41.00	15.30	101.6

Application Notes
Metal protective cover for jam nut receptacle connectors with stainless steel chain or nylon cord.

TABLE II: MODIFICATION CODES

Shell Finish (Omit for Standard Cad/Olive Drab Finish)
F6 - Black Electrodeposited Paint (RoHs)
F7 - Black Zinc Nickel (RoHs)
F11 - Electroless Nickel (RoHs)
MB - Marine Bronze (RoHs)