

# SERIES 80 MIGHTY MOUSE CONNECTORS Accessories, Backshells, and Tools




## Dummy Stowage Receptacle for Series 805 Connectors



657-079

| How To Order                 |                                                                                                                                                                                                                                                                                                                                                                                                                                                                                                 |    |    |
|------------------------------|-------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------|----|----|
| Sample Part Number           | 657-079                                                                                                                                                                                                                                                                                                                                                                                                                                                                                         | NF | 15 |
| Series                       | 657-079 = Universal Polarity                                                                                                                                                                                                                                                                                                                                                                                                                                                                    |    |    |
| Shell Material and Finish    | <b>C</b> = Aluminum / Black Anodize<br>(Non-Conductive) RoHS Compliant<br><b>M</b> = Aluminum / Electroless Nickel<br><b>NF</b> = Aluminum / Cadmium with Olive Drab<br><b>ZN</b> = Aluminum / Zinc-Nickel with Olive Drab Chromate<br><b>ZNU</b> = Aluminum / Zinc-Nickel with Black over Electroless Nickel<br><b>Z1</b> = Stainless Steel / Passivated<br><b>ZB</b> = Stainless Steel / Olive Drab Chromate over Cadmium<br><b>ZC</b> = Stainless Steel / Zinc Cobalt Alloy / Black Chromate |    |    |
| Shell Size<br>(See Table II) | 8, 9, 10, 11, 12, 13, 15, 18, 19, 21, 23                                                                                                                                                                                                                                                                                                                                                                                                                                                        |    |    |

These Series 805 dummy stowage receptacles universal polarity provide a safe a convenient place to store and protect cabled connectors when not in use due to routine maintenance or repair of plug cables.

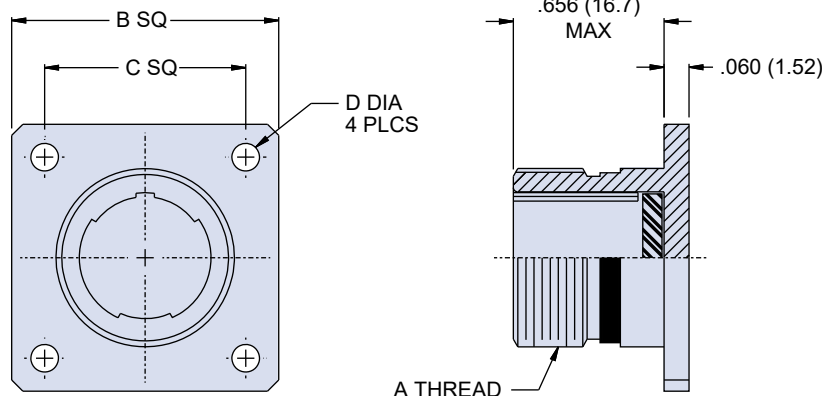

### NOTES:

- Glenair 600 series backshell assembly tools are recommended for assembly and installation.
- Material and Finish:
  - Receptacle: Al Alloy or SST/
  - Seal: Fluorosilicone

| Table II: Dimensions |                   |       |       |       |       |              |              |
|----------------------|-------------------|-------|-------|-------|-------|--------------|--------------|
| Shell Size           | A Thread 2A       | B Sq  |       | C Sq  |       | D Dia        |              |
|                      |                   | in.   | mm.   | in.   | mm.   | in.          | mm.          |
| 8                    | .5000-.1P-.3L-TS  | .850  | 21.59 | .660  | 16.76 | .097<br>.091 | 2.46<br>2.31 |
| 9                    | .5625-.1P-.3L-TS  | .913  | 23.19 | .723  | 18.36 |              |              |
| 10                   | .6250-.1P-.3L-TS  | .975  | 24.77 | .785  | 19.94 |              |              |
| 11                   | .6875-.1P-.3L-TS  | 1.039 | 26.39 | .848  | 21.54 |              |              |
| 12                   | .7500-.1P-.3L-TS  | 1.099 | 27.91 | .909  | 23.09 |              |              |
| 13                   | .8125-.1P-.3L-TS  | 1.163 | 29.54 | .973  | 24.71 | .131<br>.125 | 3.33<br>3.18 |
| 15                   | .9375-.1P-.3L-TS  | 1.288 | 32.72 | 1.058 | 26.87 |              |              |
| 18                   | 1.1250-.1P-.3L-TS | 1.475 | 37.47 | 1.255 | 31.88 |              |              |
| 19                   | 1.1870-.1P-.3L-TS | 1.537 | 39.04 | 1.327 | 33.71 |              |              |
| 21                   | 1.3125-.1P-.3L-TS | 1.663 | 42.24 | 1.452 | 36.88 |              |              |
| 23                   | 1.4375-.1P-.3L-TS | 1.787 | 45.39 | 1.570 | 39.88 |              |              |