



SERIES 801 DOUBLE-START ACME THREAD Mighty Mouse Connectors and Cables

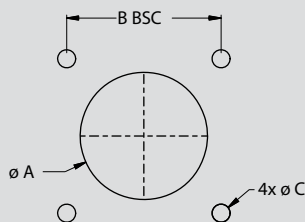

Panel Cut-Out Dimensions and Key / Keyway Positions and Polarization

PANEL CUT-OUT POSITIONS

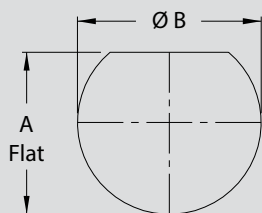


Jam-Nut, Rear Panel Mount		
Shell Size	A Flat	Ø B
5	.358 (9.09)	.385 (9.78)
	.354 (8.99)	.380 (9.65)
6	.418 (10.62)	.448 (11.38)
	.414 (10.52)	.443 (11.25)
7	.544 (13.82)	.572 (14.53)
	.540 (13.72)	.567 (14.40)
8	.544 (13.82)	.572 (14.53)
	.540 (13.72)	.567 (14.40)
9	.604 (15.34)	.635 (16.13)
	.600 (15.24)	.630 (16.00)
10	.668 (16.97)	.698 (17.73)
	.664 (16.87)	.693 (17.60)
11	.726 (18.44)	.760 (19.30)
	.722 (18.34)	.755 (19.18)
13	.853 (21.67)	.885 (22.48)
	.849 (21.56)	.880 (22.35)
16	1.030 (26.16)	1.072 (27.23)
	1.026 (26.06)	1.067 (27.10)
17	1.104 (28.04)	1.135 (28.83)
	1.100 (27.94)	1.130 (28.70)
19	1.235 (31.37)	1.260 (32.00)
	1.231 (31.27)	1.255 (31.88)
21	1.355 (34.42)	1.385 (35.18)
	1.351 (34.32)	1.380 (35.05)

Square Flange			
Shell Size	Ø A	B BSC	Ø C
5	.328 (8.33)	.363 (9.22)	.096 (2.44)
			.091 (2.31)
6	.390 (9.91)	.423 (10.74)	.096 (2.44)
			.091 (2.31)
7	.453 (11.51)	.483 (12.27)	.096 (2.44)
			.091 (2.31)
8	.515 (13.08)	.545 (13.84)	.096 (2.44)
			.091 (2.31)
9	.578 (14.68)	.607 (15.42)	.130 (3.30)
			.126 (3.20)
10	.640 (16.26)	.670 (17.02)	.130 (3.30)
			.126 (3.20)
11	.703 (17.86)	.715 (18.16)	.130 (3.30)
			.126 (3.20)
13	.828 (21.03)	.812 (20.62)	.130 (3.30)
			.126 (3.20)
16	1.015 (25.78)	.981 (24.92)	.130 (3.30)
			.126 (3.20)
17	1.078 (27.38)	1.060 (26.92)	.130 (3.30)
			.126 (3.20)
19	1.203 (30.56)	1.191 (30.25)	.130 (3.30)
			.126 (3.20)
21	1.328 (33.73)	1.322 (33.58)	.130 (3.30)
			.126 (3.20)


POLARIZATION

Plug Key Positions

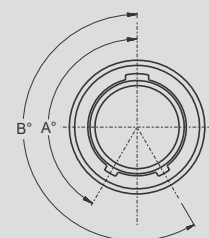

Position	A°	B°
A	150°	210°
B	75°	210°
C	95°	230°
D	140°	275°
E	75°	275°
F	95°	210°

Receptacle Keyway Positions

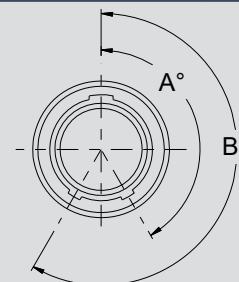

Position	A°	B°
A	150°	210°
B	75°	210°
C	95°	230°
D	140°	275°
E	75°	275°
F	95°	210°