

New Mighty Mouse Layouts with Size #8 Quadrax, Twinax, Coax or Power Contacts

Table of Contents and Introduction



Mighty Mouse
with #8 Contacts

PRODUCT SELECTION GUIDE

K



Series 801 Plug and Receptacle Connectors

Rugged double-start ACME mating threads.

Page K-6



Series 805 Plug and Receptacle Connectors

Rugged Triple-Start ACME mating threads, EMI ground spring, ratchet anti-decoupling mechanism.

Page K-13



#8 Power Contacts

Power contacts are supplied with connectors or ordered separately.

Page K-19



75 Ohm Coax Contacts for High-Frequency Video

DC - 4GHz. For RS170 and SMPTE 292M video cables.

Page K-21



50 Ohm Coax Contacts for LLSB-200 Low Loss Cable

DC - 2.5GHz.

Page K-23



Quadrax Contacts for 100BASE-T Ethernet

Size 8 multi-pin contacts with four signal pins and an outer contact body. Used for ARINC 664 100BASE-T Ethernet

Page K-25



Concentric Twinax Contacts for MIL-STD-1553 Databus

Page K-27




100 Ohm Differential Twinax Contacts for Controlled Impedance Shielded Pair Cable

Page K-29



Coax Contacts for Rg180 Cable

Page K-31

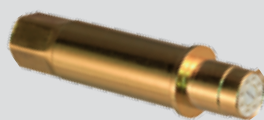

100 Ohm El Ochito® Contacts for 10G Ethernet

Page K-33

Dimensions in Inches (millimeters) are subject to change without notice.