


260-002-74 Jam-Nut Mount Receptacle MS3474

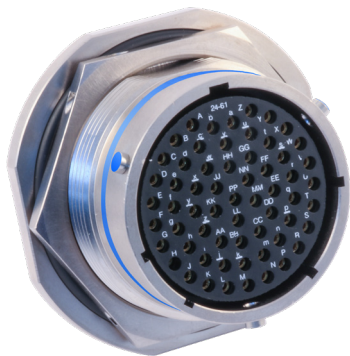


GLENAIR SERIES 260

MIL-DTL-26482 Series II Type



260-002-74 Jam-Nut Mount Receptacle MS3474

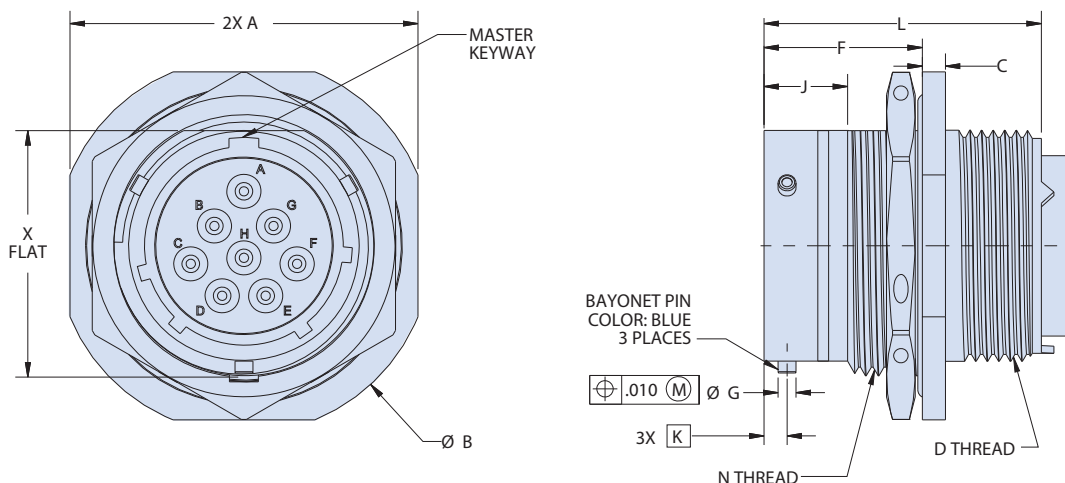

DIMENSIONS											
Shell Size	A	B	X Flat	N Thread	D Thread	ØG	K Bsc	C	L Max	F	J
8	.954 (24.23)	1.078 (27.38)	.525 (13.34)	.5625-24 UNEF-2A	.5000-20 UNF-2A	.084 (2.13)	.100 (2.54)	.113 (2.87)	1.215 (30.86)	.707 (17.96)	.378 (9.60)
	.923 (23.44)	1.047 (26.59)				.076 (1.93)		.086 (2.18)		.658 (16.71)	.346 (8.79)
10	1.078 (27.38)	1.203 (30.56)	.650 (16.51)	.6875-24 UNEF-2A	.6250-24 UNEF-2A	.084 (2.13)	.100 (2.54)	.113 (2.87)	1.215 (30.86)	.707 (17.96)	.378 (9.60)
	1.047 (26.59)	1.172 (29.77)				.076 (1.93)		.086 (2.18)		.658 (16.71)	.346 (8.79)
12	1.266 (32.16)	1.391 (35.33)	.813 (20.65)	.8750-20 UNEF-2A	.7500-20 UNEF-2A	.084 (2.13)	.100 (2.54)	.113 (2.87)	1.215 (30.86)	.707 (17.96)	.378 (9.60)
	1.235 (31.37)	1.360 (34.54)				.076 (1.93)		.086 (2.18)		.658 (16.71)	.346 (8.79)
14	1.391 (35.33)	1.516 (38.51)	.937 (23.80)	1.000-20 UNEF-2A	.8750-20 UNEF-2A	.084 (2.13)	.100 (2.54)	.113 (2.87)	1.215 (30.86)	.707 (17.96)	.378 (9.60)
	1.360 (34.54)	1.485 (37.72)				.076 (1.93)		.086 (2.18)		.658 (16.71)	.346 (8.79)
16	1.516 (38.51)	1.641 (41.68)	1.061 (26.95)	1.1250-18 UNEF-2A	1.000-20 UNEF-2A	.084 (2.13)	.100 (2.54)	.113 (2.87)	1.215 (30.86)	.707 (17.96)	.378 (9.60)
	1.485 (37.72)	1.610 (40.89)				.076 (1.93)		.086 (2.18)		.658 (16.71)	.346 (8.79)
18	1.641 (41.68)	1.766 (44.86)	1.186 (30.12)	1.2500-18 UNEF-2A	1.0625-18 UNEF-2A	.084 (2.13)	.100 (2.54)	.113 (2.87)	1.215 (30.86)	.707 (17.96)	.378 (9.60)
	1.610 (40.89)	1.735 (44.07)				.076 (1.93)		.086 (2.18)		.658 (16.71)	.346 (8.79)
20	1.828 (46.43)	1.954 (49.63)	1.311 (33.30)	1.3750-18 UNEF-2A	1.1875-18 UNEF-2A	.084 (2.13)	.100 (2.54)	.148 (3.76)	1.275 (32.39)	.772 (19.61)	.378 (9.60)
	1.797 (45.64)	1.923 (48.84)				.076 (1.93)		.096 (2.44)		.721 (18.31)	.346 (8.79)
22	1.954 (49.63)	2.078 (52.78)	1.436 (36.47)	1.5000-18 UNEF-2A	1.3125-18 UNEF-2A	.084 (2.13)	.100 (2.54)	.148 (3.76)	1.275 (32.39)	.772 (19.61)	.378 (9.60)
	1.923 (48.84)	2.047 (51.99)				.076 (1.93)		.096 (2.44)		.721 (18.31)	.346 (8.79)
24	2.078 (52.78)	2.203 (55.96)	1.561 (39.65)	1.6250-18 UNEF-2A	1.4375-18 UNEF-2A	.131 (3.33)	.109 (2.77)	.148 (3.76)	1.275 (32.39)	.772 (19.61)	.405 (10.29)
	2.047 (51.99)	2.172 (55.17)				.123 (3.12)		.096 (2.44)		.721 (18.31)	.379 (9.63)

PANEL MOUNT					
	Shell Size	ØH		E Flat	
	8	.572	14.53	.536	13.61
	10	.697	17.70	.661	16.79
	12	.895	22.73	.824	20.93
	14	1.010	25.65	.948	24.08
	16	1.135	28.83	1.072	27.23
	18	1.260	32.00	1.197	30.40
	20	1.385	35.18	1.322	33.58
	22	1.510	38.35	1.447	36.75
	24	1.635	41.53	1.572	39.93