

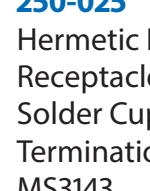
 
THREADED COUPLING, MIL-DTL-5015 TYPE Harsh Environment Power and Signal Interconnects



Glass-to-Metal Seal Hermetic Connector Product Selection Guide Series I

HERMETIC CONNECTORS

MIL-DTL-1651 Type Insert Arrangements	2
MIL-DTL-5015 Type Alternate Key Positions	4
Space Grade Application Guidelines	23
Connector Modification Codes and Catalog Notes	24
Hermetic Connector Designer’s Application Checklist	25

Part	Part Number and Description	Page No.	Part	Part Number and Description	Page No.
	250-013 Hermetic Jam-Nut Mount Receptacle, Pin or Socket Contact, Solder Cup or Eyelet Termination MS3142	24		250-025 Hermetic Flangeless Mount Receptacle, Pin Contacts, Solder Cup or Eyelet Termination MS3143	30
	250-014 Hermetic Solder Mount Receptacle, Pin Contacts, Solder Cup or Eyelet Termination MS3143	26		250-105 Hermetic Jam-Nut Receptacle, Pin Contacts, Solder Cup and PC Tail Termination MS3404	32
	250-016 Hermetic Solder Mount Receptacle, Socket Contacts, Solder Cup or Eyelet Termination MS3143 Type	28		250-106 Hermetic Bulkhead Feed-Thru, Jam-Nut Mount, Pin-Socket, Pin-Pin, and Socket-Socket Contacts	34

VISIT CATALOG