


SERIES 89 NANOMINIATURE Dual-Row Rectangular Connectors




899-015 Nano Rear Panel Mount Gasket

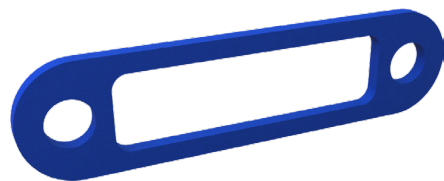

Replacement Gasket Seals offered as a replacement for lost or damaged rear panel mount Nano Miniature gasket seals. Available for all shell sizes in fluorosilicone, Passivated Silver Plated Aluminum Filled Fluorosilicone, Nickel Plated Aluminum Filled Fluorosilicone, and Viton.

HOW TO ORDER NANO DUAL-ROW EMI COVER			
Sample Part Number	899-015	-25	-01
Series	899-015 = Nano Rear Panel Mount Gasket		
Connector Size	9, 15, 21, 25, 31, 37, 41, 51, 65, 69, 85, 91; See Dimensions Table		
Gasket Material	01 = Fluorosilicone IAW MIL-DTL-25988 Type II, Class I, Grade 60 02 = Passivated Silver Plated Aluminum Filled Fluorosilicone IAW MIL-DTL-83528, Type "D" (CHO-SEAL 1298 or Equivalent) 03 = Nickel Plated Aluminum Filled Fluorosilicone, (CHO-SEAL 6503 or equivalent) 04 = Viton, 75 Shore A, IAW ASTM D1418 / ISO 1629 Designation FKM, ASTM D2000 / SAE J200 Type/Class HK, MIL-R-3065 Class TB.		

DIMENSIONS			
Part Number	A	B	C
899-015-09-XX	.768 (19.51)	.566 (14.38)	.240 (6.10)
899-015-15-XX	.843 (21.41)	.641 (16.28)	.240 (6.10)
899-015-21-XX	.918 (23.32)	.716 (18.19)	.240 (6.10)
899-015-25-XX	.968 (24.59)	.766 (19.46)	.240 (6.10)
899-015-31-XX	1.043 (26.49)	.841 (21.36)	.240 (6.10)
899-015-37-XX	1.118 (28.40)	.916 (23.27)	.240 (6.10)
899-015-41-XX	1.168 (29.67)	.966 (24.54)	.240 (6.10)
899-015-51-XX	1.293 (32.84)	1.091 (27.71)	.240 (6.10)
899-015-65-XX	1.468 (37.29)	1.266 (32.16)	.240 (6.10)
899-015-69-XX	1.518 (38.56)	1.316 (33.43)	.240 (6.10)
899-015-85-XX	1.770 (44.96)	1.568 (39.83)	.265 (6.73)
899-015-91-XX	1.845 (46.86)	1.643 (41.73)	.265 (6.73)

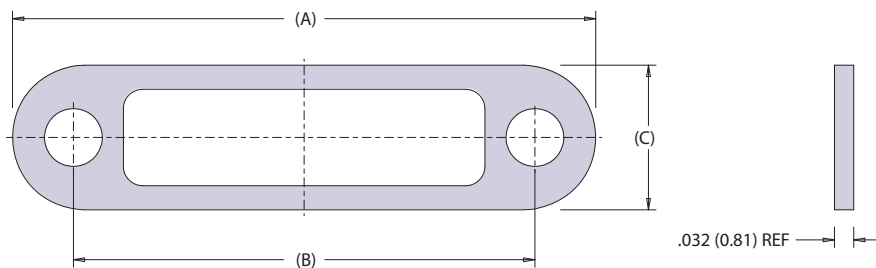

DUAL-ROW RECTANGULAR CONNECTORS