

SERIES 89 NANOMINIATURE Rectangular and Circular Connectors




Product Selection Guide

Glenair Nanominiature Connector Specifications


Nano Connector Line Overview	A-2	Single Row Contact Arrangements	A-15
Performance Summary, Materials and Finishes	A-4	Dual Row Contact Arrangements	A-16
MIL-DTL-32139 Connector Specifications	A-5	Circular Contact Arrangements	A-17
Modification Codes	A-11	and Keyway Positions	
RoHS Compliance Information	A-12		

Nano Rectangular Single-Row Connectors and Accessories

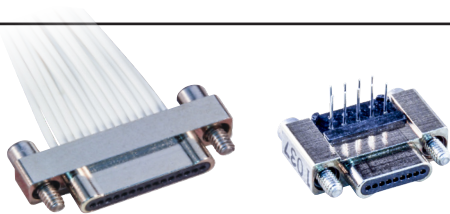


M32139 type single-row nanominiature rectangular connectors. Termination options include prewired, solid wire and PCB. Connector savers and EMI protective covers are also available.

Nano Rectangular Dual-Row Connectors and Accessories

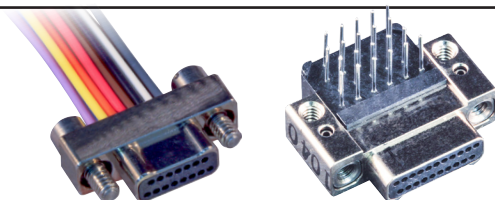


M32139 type dual-row rectangular nano connectors. Prewired – insulated or solid wire, PCB thru-hole, surface mount, straddle mount or back to back cable configurations. Connector savers and EMI protective covers also available.

MIL-DTL-32139 Qualified Connectors and Accessories

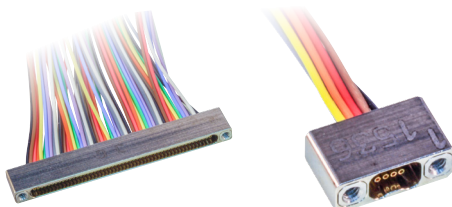

MIL-DTL-32139 qualified single or dual row prewired. Single row PCB thru-hole connectors available as vertical mount or right angle.

Nano-Strip Connectors

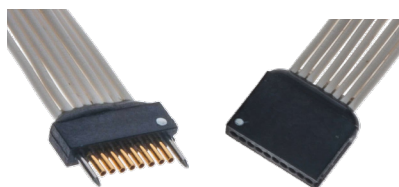

Nano Strip single and dual row plastic shell connectors. Surface mount, insulated wire, uninsulated wire and thru-hole connectors.

Nano Circular Connectors and Accessories



Pre-wired and PCB thru-hole mount circular nano plug and receptacle connectors with threaded or breakaway interfaces. Available receptacle mounting configurations include front panel mount, rear panel mount, and inline.