


General Information


Product Line Overview	A-2	Dust Covers	A-13
Performance Summary, Materials and Finishes	A-4	Single Row Contact Arrangements	A-14
MIL-DTL-32139 Connector Specifications	A-5	Dual Row Contact Arrangements	A-15
Modification Codes	A-8	Circular Contact Arrangements and Keyway Positions	A-16
RoHS Compliance Information	A-12		

Circular Connectors

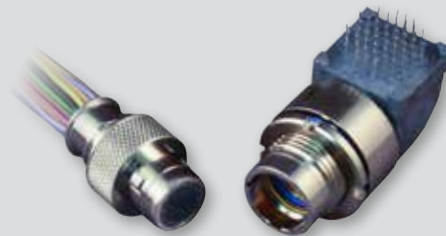


Pre-wired and PCB thru-hole mount circular plug and receptacle connectors with threaded or breakaway interfaces. Available receptacle mounting configurations include front panel mount, rear panel mount and inline.

Rectangular Single Row Connectors

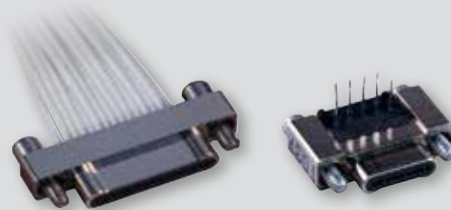


M32139 type single row rectangular connectors. Termination options include prewired, solid wire and PCB. Connector savers and EMI protective covers are also available.

Rectangular Dual Row Connectors

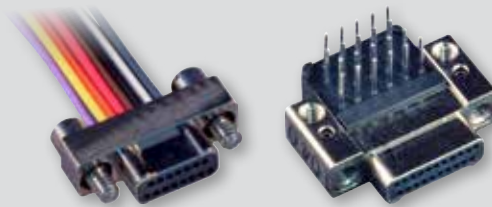

M32139 type dual row rectangular connectors. Prewired – insulated or solid wire, PCB thru-hole, surface mount, straddle mount or back to back cable configurations. Connector savers and EMI protective covers also available.

MIL-DTL-32139 Connectors

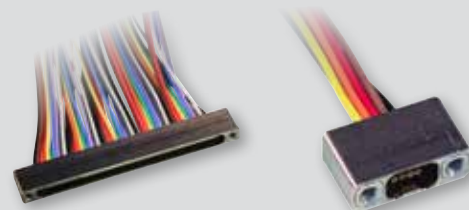

MIL-DTL-32139 single or dual row prewired. Single row PCB thru-hole connectors available as vertical mount or right angle.

Index

