

Series 806 Mil-Aero PowerPlay
620V*080 Metal Strain Relief Cable Clamp



HOW TO ORDER			
Sample Part Number	620VS080	MT	08
Basic Part Number	620VS080 = Straight Strain Relief 620VB080 = 45° Strain Relief 620VA080 = 90° Strain Relief		
Material/ Finish	ME = Aluminum, Electroless Nickel MT = Aluminum, Ni/PTFE ZR = Aluminum, Black Zinc-Nickel NF = Aluminum, Olive Drab Cadmium		
Shell Size	11, 14, 16, 18, 20		

SPECIFICATIONS

- Operating temperature:
codes ME and MT: -65°C to +200°C
codes ZR, NF, NFP: -65°C to +175°C
- Salt spray (corrosion)
Code ME: 96 hours
Code NF, ZR, MT: 1000 hours
- Vibration, shock: SAE AS85049
Category 4C


FEATURES

- Straight, 45° and 90°
- Self-locking spin coupling
- Fits Series 806 micro miniature connectors
- Captive threaded inserts

MATERIAL/FINISH

- Clamp, body, saddles, coupling nut: aluminum alloy. See material/finish options in How to Order table for options.
- Hardware: 300 series stainless steel
- Anti-decoupling device: corrosion-resistant material

DIMENSIONS

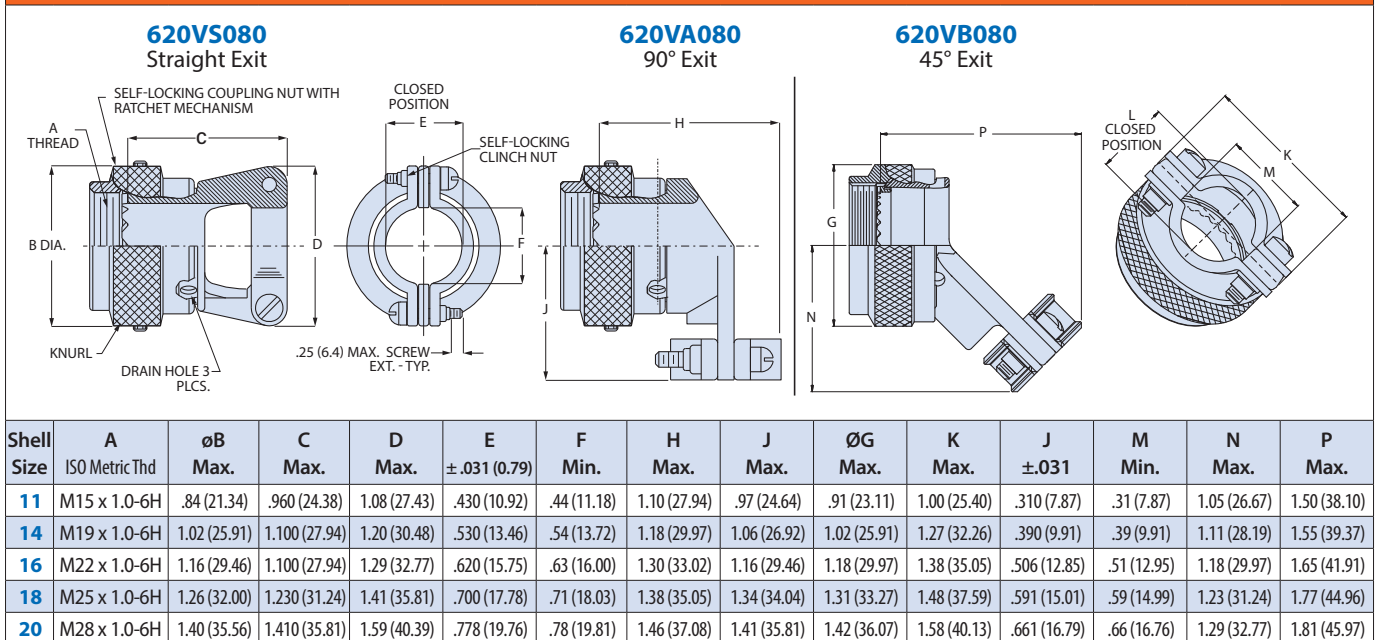

SERIES 806 MIL-AERO POWERPLAY HIGH DENSITY