



SuperNine Series III PowerPlay Triple-Start
660-137 Receptacle Cover

SUPER NINE SERIES III POWERPLAY TRIPLE-START



HOW TO ORDER						
Sample Part Number	660-137	NF	19	R	6	-01
Basic Part Number	660-137 PowerPlay Receptacle Cover					
Material/Finish	ME = Aluminum Alloy, Electroless Nickel MT = Aluminum Alloy, Nickel-PTFE NF = Aluminum Alloy, Cad/O. D. Over Electroless Nickel (1000 Hour Salt Spray) ZR = Aluminum Alloy, Zinc Nickel, Black Z1 = 300 SST, Passivate					
Shell Size	11, 13, 15, 17, 19, 21, 23, 25					
Attachment Type	See Attachment Rings Style Table					
Attachment Length	In Inches					
Ring Style Dash Number	See Attachment Rings Table					

MATERIAL/FINISH


- Cover: see Material/Finish Table
- Hardware, rivet: CRES/passivate
- Sealant, rivet: 2 part epoxy
- Rope attachments: Per Attachment Rings Style Table
- Anti-decoupling device: corrosion resistant material

NOTES

- Max diameter over which mandrel will rotate freely shown in Attachment Ring Table.
- Length tolerance for sash chain (s) is ± one (1) link, for all other attachments ± .25.

ATTACHMENT RING							
Style A		Style B		Style C		Style D	
Dash Number	C Dia	Dash Number	D Dia	Dash Number	E Dia	Dash Number	F Dia
085	0.265 (6.73)	08	0.468 (11.89)	50	0.425 (10.80)	01	0.140 (3.56)
095	0.312 (7.92)	10	0.593 (15.06)	52	0.485 (12.32)	02	0.182 (4.62)
100	0.391 (9.93)	12	0.718 (18.24)	54	0.640 (16.26)	03	0.191 (4.85)
101	0.516 (13.11)	14	0.844 (21.44)	56	0.750 (19.05)	04	0.197 (5.00)
102	0.583 (14.81)	16	0.968 (24.59)	58	0.890 (22.61)	05	0.167 (4.24)
103	0.641 (16.28)	18	1.093 (27.76)	60	1.015 (25.78)	06	0.125 (3.18)
104	0.708 (17.98)	20	1.187 (30.15)	62	1.095 (27.81)	07	0.218 (5.54)
105	0.766 (19.46)	22	1.343 (34.11)	64	1.130 (28.70)	09	0.156 (3.96)
106	0.896 (22.76)	24	1.484 (37.69)	66	1.250 (31.75)	00	No Eyelet
107	1.016 (25.81)	28	1.687 (42.85)	68	1.350 (34.29)	Style RL SEE DRAWING 677-048	
108	1.141 (28.98)	32	1.968 (49.99)	70	1.375 (34.92)		
109	1.266 (32.16)	36	2.187 (55.55)	72	1.485 (37.72)		
110	1.391 (35.33)	40	2.406 (61.11)	74	1.625 (41.28)		
111	1.521 (38.63)	44	2.656 (67.46)	76	1.750 (44.45)		
112	1.641 (41.68)	48	3.031 (76.99)	78	1.875 (47.63)		
113	1.766 (44.86)			80	1.980 (50.29)		
114	1.891 (48.03)			82	2.060 (52.32)		
115	2.078 (52.78)			84	2.235 (56.77)		
116	2.406 (61.11)			86	2.310 (58.67)		
117	2.510 (63.75)			88	2.475 (62.87)		
				90	2.655 (67.44)		
				92	2.810 (71.37)		
				94	3.045 (77.34)		

SuperNine Series III PowerPlay Triple-Start
660-137 Receptacle Cover

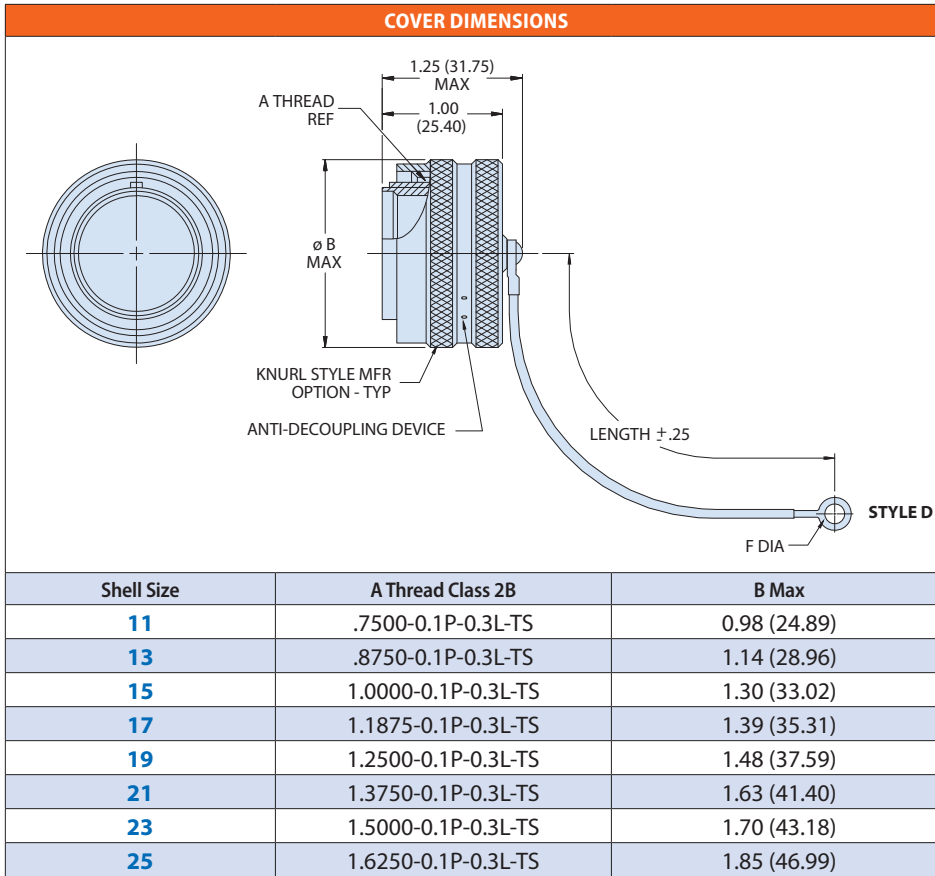

ATTACHMENT TYPE

Wire Rope
Types F, G, H, K, R, T, U

Sash Chain
Type S

Symbol	Attachment
F	Wire Rope, Nylon Jacket with Terminal
G	.094 Dia Nylon Cord (Black) with Loop Ends
H	Wire Rope, Teflon Jacket with Terminal
N	Attachment Omitted
NB	No Lanyard or Attachment Boss
R	Wire Rope, PVC Jacket with Terminal
T	Wire Rope, No Jacket, with Terminal
K	Nylon Rope
S	#8 Sash Chain, CRES, Passivate
U	Wire Rope, Polyurethane Jacket

SUPERNINE SERIES III POWERPLAY TRIPLE-START