
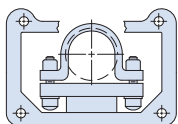


DPX / AS81659

507-249

Saddle Clamp Strain Relief, AS81659

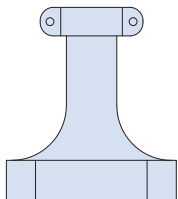

507-249

Saddle-clamp backshell fits AS81659 connectors

Available in three mounting styles. Aluminum with stainless steel screws and washers. Captivated nut is silver-plated SST.

PART NUMBER

Sample PN →

507-249

M

B

H


Base P/N **507-249**

Finish
M Electroless Nickel
JF Cadmium with Yellow Chromate
TZ Tin-Zinc
NF Olive Drab Cadmium


Mounting
A Angle Mount Left
B Back Mount
C Angle Mount Right

Mounting Hardware
Omit No Hardware
H Hardware Included (4) #2-56 screws and (4) lockwashers


507-249*B BACK MOUNT

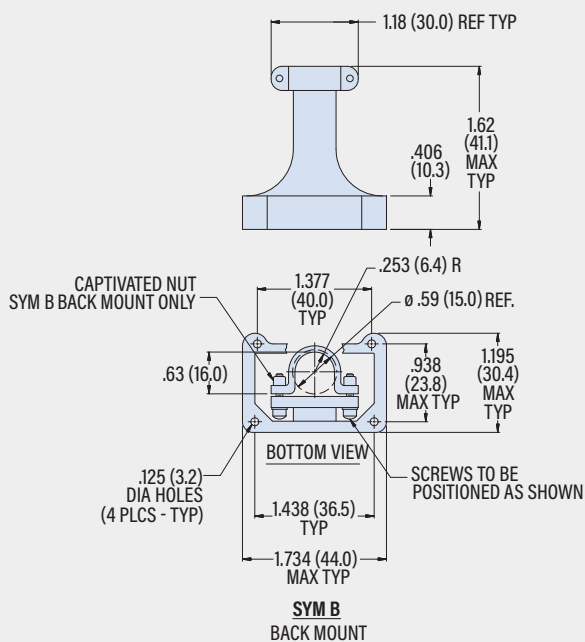

507-249*A AND C ANGLE MOUNT LEFT AND RIGHT

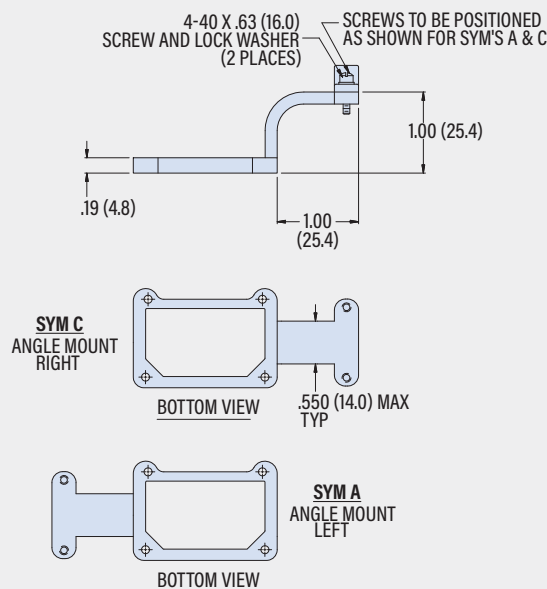

MOUNTING HARDWARE "H" OPTION

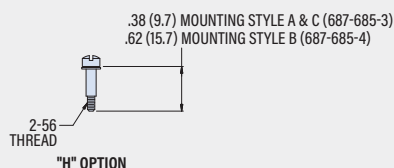

DPX / AS81659 BACKSHELLS