

 
AS81659 / DPX Backshell Selection Guide

DPX / AS81659 BACKSHELLS


AS81659 Strain Reliefs



AS81659 Saddle Clamp Backshell
507-001
Page F-2



 AS81659 Qwik-Ty Strain Relief
507-002
Page F-3



AS81659 Saddle Clamp Strain Relief
507-249
Page F-4

AS81659 EMI Backshells



AS81659 EMI Banding Backshell
507-011
Page F-5



AS81659 EMI TAG Ring Backshell
507-059
Page F-6



AS81659 EMI M25 Backshell
507-117
Page F-7




AS81659 EMI Cone-and-Ring Backshell
527-083
Page F-8




AS81659 EMI Banding Split Composite Backshell
527-476
Page F-9

DPX EMI Backshells

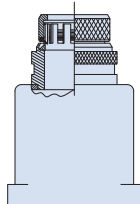

DPX2 EMI TAG Ring Backshell
527-070
Page F-10

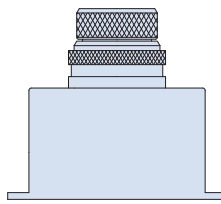

DPX4 EMI TAG Ring Backshell
527-142
Page F-11