


Band-Master ATS®

Shield Termination Bands and Tools

Band-Master ATS®

Terminate cable braid shield to adapter with stainless steel **Band-Master ATS®** bands. Install band with hand tool or bench-mounted pneumatic tool. Bands are available in *Standard* (.24 inch) and *Micro* (.12 inch) widths. *Slim Standard* and *Micro Slim* bands have reduced thickness for weight reduction. Hardened steel *Micro-Max* bands have 60% more tensile strength than standard Micro bands. Available pre-coiled, bands are 304 series stainless steel, passivated.

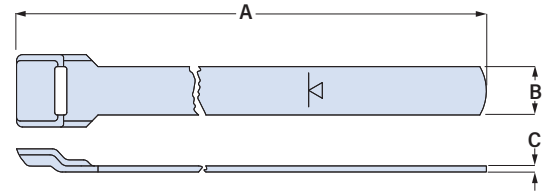

For more information on the Band-Master ATS EMI shield termination system, including instruction manuals and calibration details:

<https://www.glenair.com/bandmaster/>

Band and Band Tool Part Numbers

Size	A Length		Fits up to Dia.		B Width		C Thickness		Part Number Pre-coiled	Hand Tool Part Number	
	in	mm	in	mm	in	mm	in	mm			
Standard		9	228	1.00	25.4	.24	6.1	.02	0.5	601-006	601-100
		14	355	1.80	45.7	.24	6.1	.02	0.5	601-041	
		18	457	2.50	63.5	.24	6.1	.02	0.5	601-050	
Slim Standard		9	228	.94	23.9	.24	6.1	.01	0.3	601-571	601-109
		14	355	1.80	45.7	.24	6.1	.01	0.3	601-573	
Micro		5	127	.50	12.7	.12	3.0	.015	0.4	601-025	601-101
		8	203	.88	22.4	.12	3.0	.015	0.4	601-061	
		14	356	1.88	47.7	.12	3.0	.015	0.4	601-065	
Micro Slim		8	203	.88	22.4	.12	3.0	.01	0.3	601-601	601-122
		14	356	1.88	47.7	.12	3.0	.01	0.3	601-603	
Micro-Max		8	203	.88	22.4	.12	3.0	.015	0.4	601-701	601-129
		14	356	1.88	47.7	.12	3.0	.015	0.4	601-703	

SERIES 79 MICRO-CRIMP ACCESSORIES