
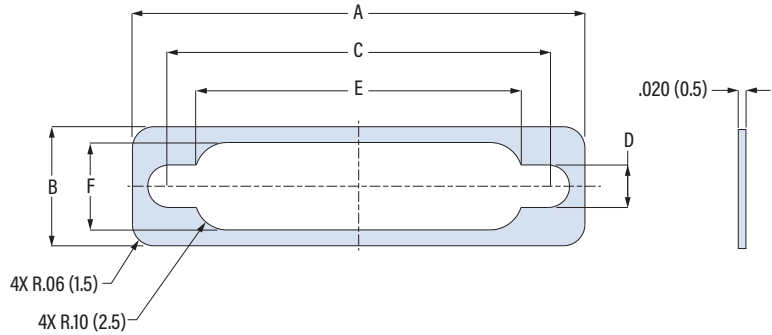


Micro-D

179-135

EMI Gasket, Panel Mount

- For MWDM and M83513 Class M
- Conductive Fluorosilicone
- Rear Panel Mount

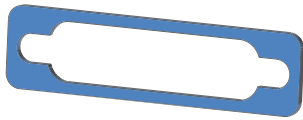

179-135

This accessory fits MWDM and M83513 Class M metal shell Micro-D connectors.

Rear mount, conductive. EMI panel gasket fits standard MWDM metal shell Micro-D connectors and M83513 Class M connectors. Gasket material is Chomerics CHO-Seal 1298 / MIL-DTL-83528 Type D. Install gasket between Micro-D flange and mounting panel for improved electrical bonding and environmental protection.

- Ag/Al filled fluorosilicone
- CHO-Seal 1298
- MIL-DTL-83528 Type D
- +200 °C
- ASTM E595 TML 0.12% CVCM
0.02%

PART NUMBER

Size	Part No.	A		B		C		D		E		F	
		in	mm	in	mm	in	mm	in	mm	in	mm	in	mm
9	179-135-9-T	.78	19.8	.35	8.9	.565	14.4	.125	3.2	.41	10.4	.26	6.6
15	179-135-15-T	.93	23.6	.35	8.9	.715	18.2	.125	3.2	.56	14.2	.26	6.6
21	179-135-21-T	1.08	27.4	.35	8.9	.865	22.0	.125	3.2	.71	18.0	.26	6.6
25	179-135-25-T	1.18	30.0	.35	8.9	.965	24.5	.125	3.2	.81	20.6	.26	6.6
31	179-135-31-T	1.33	33.8	.35	8.9	1.115	28.3	.125	3.2	.96	24.4	.26	6.6
37	179-135-37-T	1.48	37.6	.35	8.9	1.265	32.1	.125	3.2	1.11	28.2	.26	6.6
51-2	179-135-51-2-T	1.83	46.5	.35	8.9	1.615	41.0	.125	3.2	1.46	37.1	.26	6.6
51	179-135-51-T	1.43	36.3	.44	11.2	1.215	30.9	.125	3.2	1.06	26.9	.31	7.9
69	179-135-69-T	1.73	43.9	.44	11.2	1.515	38.5	.125	3.2	1.36	34.5	.31	7.9
75	179-135-75-T	2.07	52.6	.44	11.2	1.705	43.3	.146	3.7	1.46	37.1	.31	7.9
100	179-135-100-T	2.16	54.9	.55	14.0	1.800	45.7	.146	3.7	1.46	37.1	.36	9.1