

Micro-D

Anti-Static Dust Caps

For M83513 and Micro-D Connectors




MICRO-D ACCESSORIES



Anti-static dust caps fit Micro-D and MIL-DTL-83513 connectors. These caps provide electrostatic protection to sensitive equipment. These caps meet the static decay requirement of MIL-PRF-81705. Surface resistivity is greater than 1×10^5 ohms/square and less than 1×10^{12} ohms/square. Black LDPE.

DUST CAPS FOR M83513 CLASS M AND MWDM MICRO-D

Size	Part No.	A		B	
		in	mm	in	mm
9P	000-01-09-162	.524	13.3	.393	10.0
9S	000-01-09-163	.563	14.3	.428	10.9
15P	000-01-15-162	.647	16.4	.393	10.0
15S	000-01-15-163	.713	18.1	.428	10.9
21P	000-01-21-162	.824	20.9	.393	10.0
21S	000-01-21-163	.863	21.9	.428	10.9
25P	000-01-25-162	.924	23.5	.393	10.0
25S	000-01-25-163	.963	24.5	.428	10.9
31P	000-01-31-162	1.074	27.3	.393	10.0
31S	000-01-31-163	1.113	28.3	.428	10.9
37P	000-01-37-162	1.224	31.1	.393	10.0
37S	000-01-37-163	1.263	32.1	.428	10.9
51P	000-01-51-162	1.174	29.8	.436	11.1
51S	000-01-51-163	1.213	30.8	.470	11.9
51-2P	000-01-51-172	1.574	40.0	.393	10.0
51-2S	000-01-51-173	1.612	40.9	.428	10.9
67P	000-01-67-162	1.974	50.1	.393	10.0
67S	000-01-67-163	2.013	51.1	.428	10.9
69P	000-01-69-162	1.474	37.4	.436	11.1
69S	000-01-69-163	1.512	38.4	.470	11.9
75P	000-01-75-162	1.574	40.0	.436	11.1
75S	000-01-75-163	1.612	40.9	.470	11.9
100P	000-01-00-162	1.574	40.0	.479	12.2
100S	000-01-00-163	1.615	41.0	.516	13.1
130P	000-01-30-162	1.947	49.5	.476	12.1
130S	000-01-30-163	1.975	50.2	.504	12.8

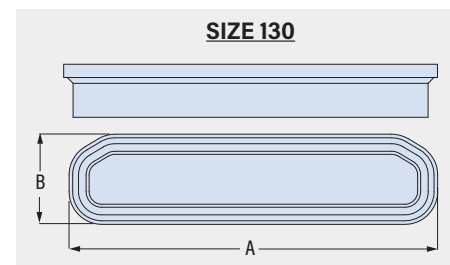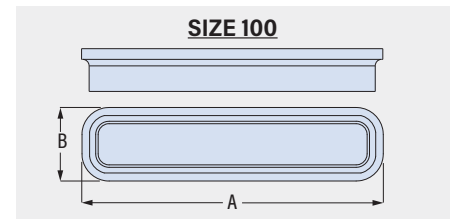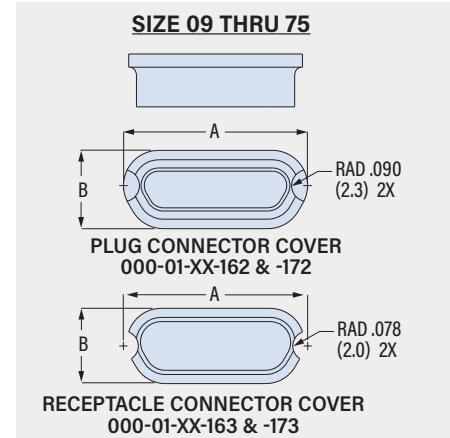

DUST CAPS FOR M83513 CLASS P AND MLDM LOW PROFILE MICRO-D

Size	Part No.	A		B	
		in	mm	in	mm
9P	000-01-09-164	.491	12.5	.349	8.9
9S	000-01-09-165	.565	14.4	.392	10.0
15P	000-01-15-164	.639	16.2	.349	8.9
15S	000-01-15-165	.715	18.2	.392	10.0
21P	000-01-21-164	.789	20.0	.349	8.9
21S	000-01-21-165	.865	22.0	.392	10.0
25P	000-01-25-164	.889	22.6	.349	8.9
25S	000-01-25-165	.965	24.5	.392	10.0
31P	000-01-31-164	1.039	26.4	.349	8.9
31S	000-01-31-165	1.115	28.3	.392	10.0
37P	000-01-37-164	1.189	30.2	.349	8.9
37S	000-01-37-165	1.265	32.1	.392	10.0
51P	000-01-51-164	1.139	28.9	.390	9.9
51S	000-01-51-165	1.215	30.9	.435	11.0

