

# Modular Rectangular (EPXB, BACC65, EN4165, SIM)



## 527-410

### EMI Backshell, BACC65AA/AB, EPXB2

- Low Profile 1" Can Height
- Band-Master ATS Shield Termination
- Qwik-Ty Strain Relief




### 527-410

This EMI banding backshell fits BACC65AA/AB and EPXB2 connectors

Split diecast EMI banding backshell. Low profile 1" (25.4) can height. Elliptical cable entries accommodate large wire bundles. Backshell attaches to connector with hex drive M8 center screw. Cable shields attach to backshell with .24 inch (6.1 mm) wide Band-Master ATS® banding strap. Nickel-plated aluminum with passivated stainless steel hardware.

PART NUMBER			
Sample PN →	<b>527-410</b>	<b>ME</b>	<b>S S B</b>
Base P/N	<b>527-410</b>		
Finish	<b>ME</b>	Electroless Nickel	
Port <b>X</b>	Qwik-Ty Style	<b>S</b>	Straight
Port <b>Y</b>	Qwik-Ty Style	<b>S</b>	Straight
Band	<i>Omit</i>	No Band	
	<b>K</b>	Standard Bands Included (qty. 2)	
	<b>J</b>	Slim Standard Bands Included (qty. 2)	

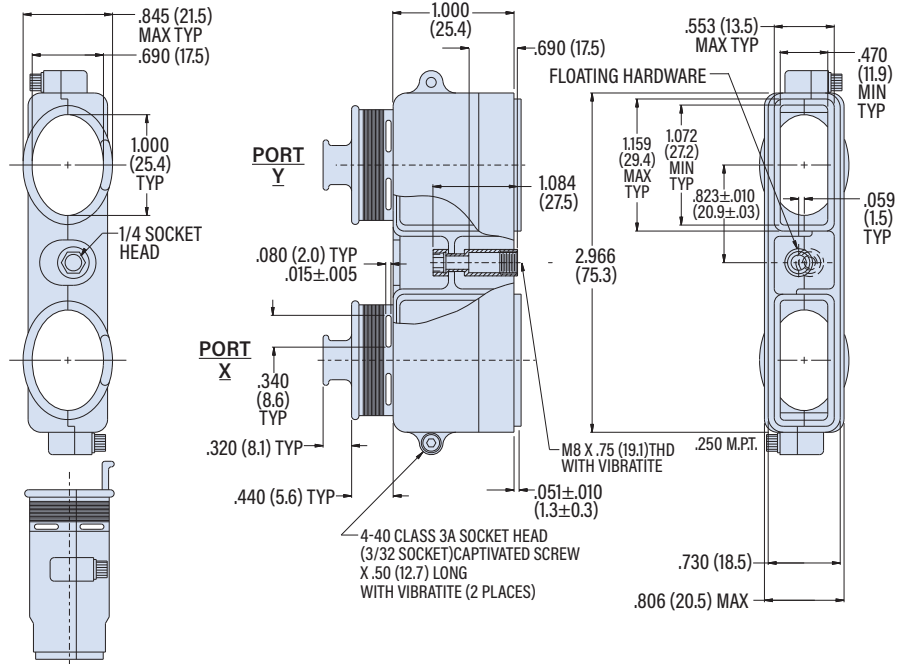

### BAND OPTIONS

Terminate cable braid to backshell with optional band strap and banding tool. Pre-coiled bands are passivated stainless steel. Slim Standard bands have reduced thickness for weight reduction.

Band Type and Width	Hand Tool	Pneumatic Tool
Standard: .24 (6.1)	<b>601-100</b>	<b>601-106</b>
Slim Standard: .24 (6.1)	<b>601-109</b>	<b>601-110</b>

MODULAR RECTANGULAR BACKSHELLS