

Series 921 Super ITS™ Connectors and Accessories

Accessories - Backshells

Backshells and Accessories for Series 921

ENVIRONMENTAL CABLE CLAMP

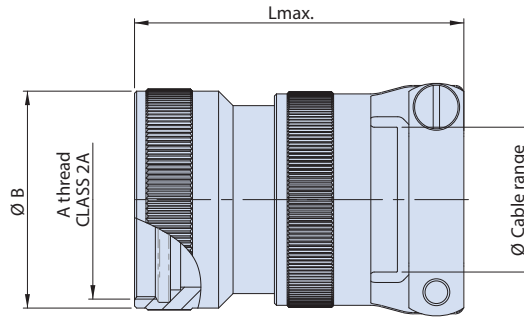


TABLE 1: DIMENSIONS

SHELL SIZE	A thread CLASS 2A	ØB max. [mm]	L max. [mm]	ØCable range [mm]		
				Option 1	Option 2	Option 3
24	1 3/8 - 18 UNEF	40	80	11,3÷19	15,5÷23,8	23,4÷31,75
28	1 5/8 - 18 UNEF	46	85	11,3÷19	15,5÷23,8	23,4÷31,75
32	1 7/8 - 16 UN	53	92	15,5÷23,8	23,4÷31,75	23,4÷35
40	2 5/16 - 16 UN	64	120	23,4÷31,75	23,4÷35	29,9÷41,25

HOW TO ORDER

MATERIAL / FINISH OPTION

SHELL SIZE	Ø Cable range [mm]	ALUMINUM	ALUMINUM	ALUMINUM	ALUMINUM	ALUMINUM	STAINLESS STEEL	MARINE BRONZE
		Black electrostatic paint	Cadmium, Olive Drab	Nickel PTFE	Electroless nickel	Anodize, Hardcoat	Passivate	Unplated
		F6	G3	MT	M	G2	Z1	AB
24	11,3÷19	921-115-24F6	921-115-24G3	921-115-24MT	921-115-24M	921-115-24G2	921-115-24Z1	921-115-24AB
	15,5÷23,8	921-116-24F6	921-116-24G3	921-116-24MT	921-116-24M	921-116-24G2	921-116-24Z1	921-116-24AB
	23,4÷31,75	921-117-24F6	921-117-24G3	921-117-24MT	921-117-24M	921-117-24G2	921-117-24Z1	921-117-24AB
28	11,3÷19	921-115-28F6	921-115-28G3	921-115-28MT	921-115-28M	921-115-28G2	921-115-28Z1	921-115-28AB
	15,5÷23,8	921-116-28F6	921-116-28G3	921-116-28MT	921-116-28M	921-116-28G2	921-116-28Z1	921-116-28AB
	23,4÷31,75	921-117-28F6	921-117-28G3	921-117-28MT	921-117-28M	921-117-28G2	921-117-28Z1	921-117-28AB
32	15,5÷23,8	921-116-32F6	921-116-32G3	921-116-32MT	921-116-32M	921-116-32G2	921-116-32Z1	921-116-32AB
	23,4÷31,75	921-117-32F6	921-117-32G3	921-117-32MT	921-117-32M	921-117-32G2	921-117-32Z1	921-117-32AB
	23,4÷35	921-118-32F6	921-118-32G3	921-118-32MT	921-118-32M	921-118-32G2	921-118-32Z1	921-118-32AB
40	23,4÷31,75	921-117-40F6	921-117-40G3	921-117-40MT	921-117-40M	921-117-40G2	921-117-40Z1	921-117-40AB
	23,4÷35	921-118-40F6	921-118-40G3	921-118-40MT	921-118-40M	921-118-40G2	921-118-40Z1	921-118-40AB
	29,9÷41,25	921-119-40F6	921-119-40G3	921-119-40MT	921-119-40M	921-119-40G2	921-119-40Z1	921-119-40AB