

852-309

852-310

- Vita 67.3

- 50 Ohm

- Nano RF

- 67 GHz



50 Ohm

Socket Contact

Pin Contact

Contacts are supplied pre-terminated from Glenair. Contact the factory for ordering information. 50 ohm. 67 GHz. Nano RF size. Snap-in, rear release high-density Nano RF coax contacts are designed to fit high-density Vita 67.3 connector modules.

PART NUMBER		
Pin Contact	Socket Contact	Cables Accommodated
852-309	852-310	962-025-047

COAX CONTACTS


MATERIAL/FINISH

- Bodies: copper alloy/gold plated
- Center contact: copper alloy/gold plated
- Insulator: high-temperature fluoropolymer
- Spring: music wire or stainless steel/passivated (spring is shipped loose from contact assembly)

ELECTRICAL PERFORMANCE

- Impedance: 50 ohms
- Frequency range: DC - 67 GHz.
- VSWR: 1.4:1 Max, DC to 40 GHz (mated pair).
1.5:1 Max, 40 GHz to 67 GHz (mated pair).

852-310 SOCKET CONTACT (MODULE)

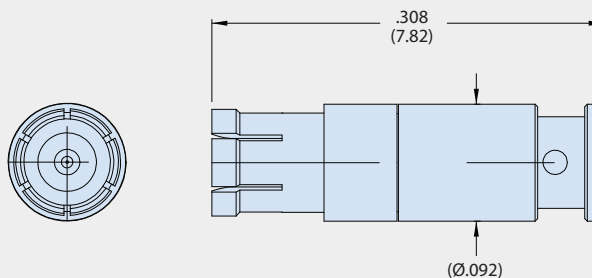

852-309 PIN CONTACT (BACKPLANE)

