

GRF05

SMA-SMA Adapters / BNC-SMA Adapters

GRF05-0028 SMP FULL-DETENT MALE TO SMA FEMALE ADAPTER




SMP Male / SMA Female. GRF05-0028 adapter has full detent SMP male connector interface. Stainless steel body, gold-plated BeCu contact, PTFE insulator.

- Frequency range: DC - 26.5 GHz
- VSWR: 1.20 maximum
- Impedance: 50 ohm

PART NUMBER

GRF05-0028

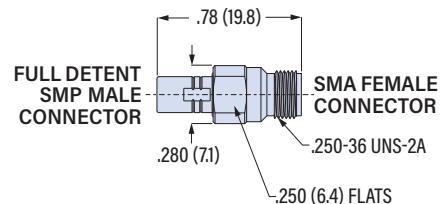

GRF05-0029 SMP SMOOTH-BORE MALE TO SMA FEMALE ADAPTER




SMP Male / SMA Female. GRF05-0029 adapter has smooth bore SMP male connector interface. Stainless steel body, gold-plated BeCu contact, PTFE insulator.

- Frequency range: DC - 26.5 GHz
- VSWR: 1.20 maximum
- Impedance: 50 ohm

PART NUMBER

GRF05-0029

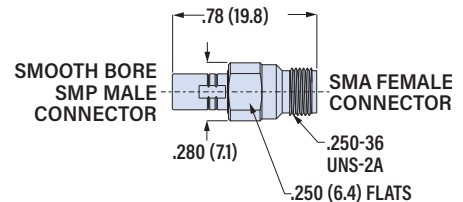

GRF05-0030 SMP FEMALE TO SMA FEMALE ADAPTER




SMP female / SMA Female. GRF05-0030 adapter connects male SMP to male SMA connector. Stainless steel body, gold-plated BeCu contact, PTFE insulator. Gold-plated BeCu anti-rock ring.

- Frequency range: DC - 26.5 GHz
- VSWR: 1.20 maximum
- Impedance: 50 ohm

PART NUMBER

GRF05-0030

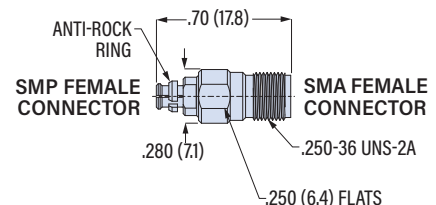

GRF05-0033 BNC MALE TO SMA FEMALE ADAPTER



BNC Male / SMA Female. GRF05-0033 adapter connects female BNC to SMA male connector. Stainless steel SMA body, nickel-plated brass BNC body and coupling nut. Gold-plated BeCu contact, PTFE insulator, nickel-plated brass wave washer. Silicone gasket.

- Operating temperature: -40 °C to +120 °C
- Frequency range: DC - 4 GHz
- VSWR: 1.20 maximum
- Impedance: 50 ohm

PART NUMBER

GRF05-0033

