



IT-MB



No Dollar
or Quantity
Minimum Orders
**NO
MINS.**

MIL-C-5015G Threaded Connectors VG95234 Compliant Marine Bronze Series

IT-MB is a threaded connector compliant with the MIL-DTL-5015 standard. All the electrical characteristics are available in the IT standard catalogue. IT-MB family is a threaded version mostly used for power and signal, frequently utilized with high-performance IP68 sealing. IP67 is considered standard performance.

For further details and drawings about these connectors, and for a wider choice of back-shell classes and connector shell styles, please refer to the related Glenair standard catalogue "IT Series Connectors"

How To Order

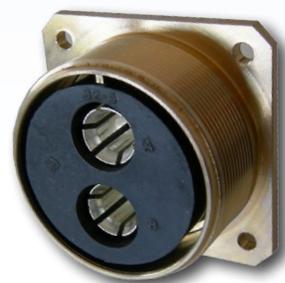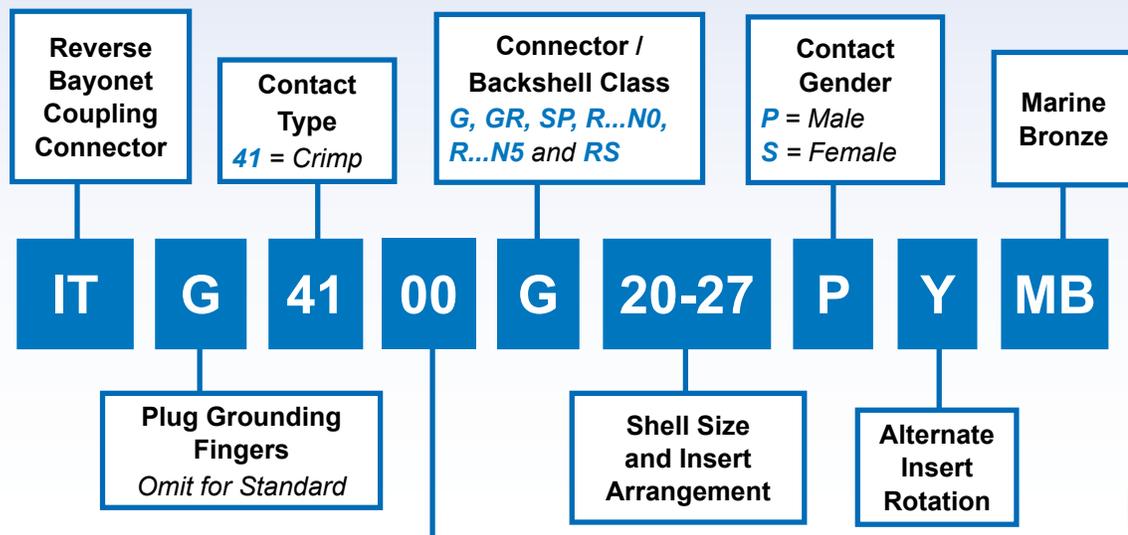

Connector Shell Styles

- 00 = Front Panel Mount Square Flange Receptacle with Accessory Threads
- 01 = In-Line Cylindrical Receptacle with Accessory Threads
- 02 = Front Panel Mount Square Flange Receptacle - No Accessory Threads
- 03 = Rear Panel Mount Square Flange Receptacle - No Accessory Threads
- 030 = Rear Panel Mount Square Flange Receptacle with Accessory Threads
- 05 = Dummy Receptacle
- 06 = Straight Cylindrical Plug Connector with Accessory Threads
- 07 = Rear Panel Mount Jam Nut Receptacle - No Accessory Threads
- 070 = Rear Panel Mount Jam Nut Receptacle with Accessory Threads
- 078 = Rear Panel Mount Jam Nut Receptacle with 90° Backshell
- 08 = Cylindrical Plug Connector with 90° Backshell
- 26 = Square Flange Panel Mount Plug
- TB = Solid Contact Bulkhead Feed Through