


BATTLE-TESTED STAR-PAN™ NG



Hubs and Accessories STAR-PAN™ NG Power Architecture

HUBS AND ACCESSORIES

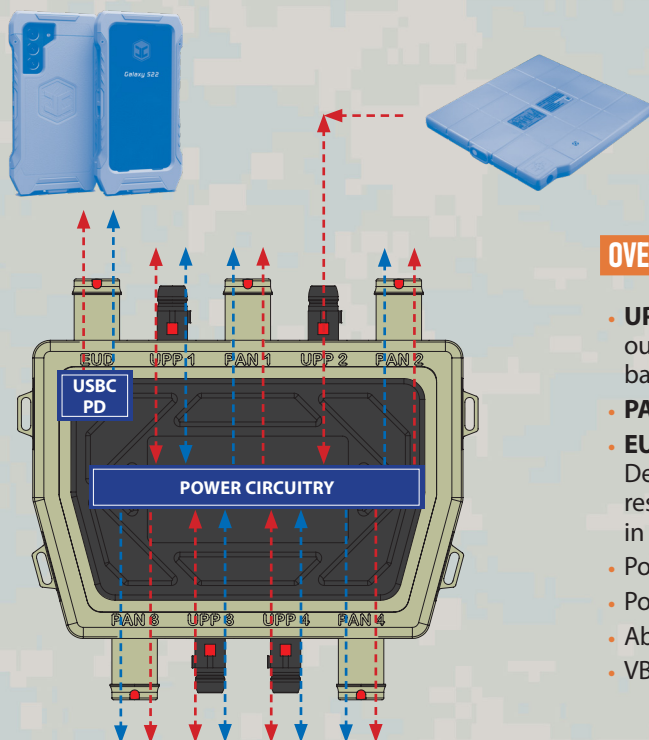

OVERVIEW

- **UPP** – Defaults as a power input but can change to power output via SPOC. Able to connect AC/DC power, soldier batteries, and radio side adapters.
- **PAN** – One directional on both **VBATT** and **VBUS** power
- **EUD** – Advanced host port mode enabling USB- C Power Delivering charge profiles of 5, 9,12,15 and 20v @ 3 amps respectively . This removes the need for previous bumps in the EUD cables
- Power input level max – 360 watts
- Power output max – 200 watts
- Able to input and output up to 10 amps of current
- VBATT power able to flow from Radio to UPP port

