



Power Cables and Battery Adapters
TS2-031 Power Conditioner, NGH

POWER CABLES AND BATTERY ADAPTERS

SPECIFICATIONS

- Enables multiple power input options and regulates power for use with STAR-PAN hubs
- Mighty Mouse 807 (NATO standard) connector [power out] and Mighty Mouse 801 connector [power in]
- 10-40V input, boosts to 12V when Voltage in is below 12V and bucks down to 20V if input Voltage is greater than 20V. By passes when input Voltage is between 12-20V. 10A out per port.

Voltage in Voltage out

Vin < 12V	12V
12V < Vin < 20V	Vin
>20V	20V

- Weight: 505g
- Export classification: EAR99

HOW TO ORDER




Part Number: TS2-031

Adapter Series Power Conditioner, NGH



QUALIFIED FOR USE WITH
STAR-PAN NG POWER / DATA HUBS

HUB PORT DESIGNATOR:
UPP

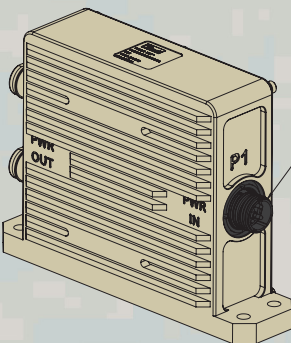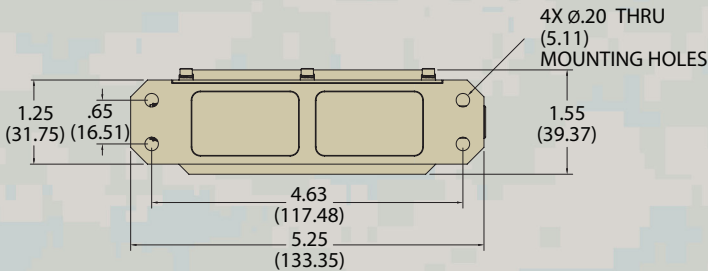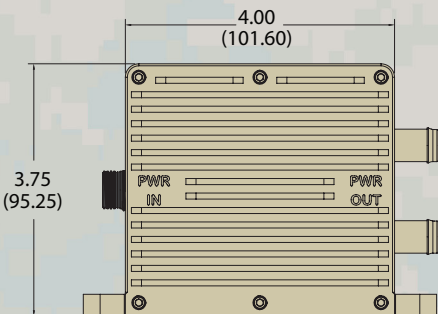

GLENAIR
CONNECTOR:
801-011-
07ZNU9-4EA

2X GLENAIR
CONNECTOR:
8070-3078-
01ZNU6P7SY

