

8572-0008 QDC Patch Cord, SuperFly-to-Standard-USB 3 Plug



Standard USB connectors. Commercial grade. Save assembly time and cost with pre-wired SuperFly Datalink "Blue" assemblies for SuperSpeed USB. Available with Type A, Type B or μ B interfaces, these cordsets have a SuperFly QDC Octaxial connector on one end and a standard USB 3 connector on the other end.


SuperFly Connector Construction

- Shell, backshell: aluminum alloy or SST
- Insulators: high-grade rigid dielectric
- Contacts: copper alloy, 50 microinches gold over nickel plating
- Grommet: fluorosilicone
- O-rings: fluorosilicone
- Bushing, retainer: copper alloy, nickel plated
- Spline: polyimide
- Cable: commercial-grade shielded USB 3 with black PVC jacket


Specifications

- Operating temp.: -0° to +80°C
- Impedance: 90 ohms
- DWV: 100 Vrms
- Current Rating: 1.5 A
- IR: 100 M Ω min.

SuperFly Connector Mating Face

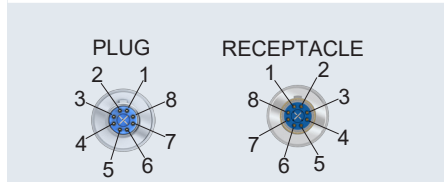

How To Order				
Sample Part Number	8572-0008	- M	-01	-24
Product	8572-0008 = Pre-wired SuperFly Datalink assembly, QDC to standard USB 3.0 connector			
Shell Finish	M = Electroless Nickel (aluminum shell) MT = Nickel-PTFE (aluminum shell) ZR = Black Zinc-Nickel (aluminum shell) ZZ = Gold (aluminum shell) ZMT = Nickel-PTFE (stainless steel shell)			
Order Code Connector Types	01 = Plug connector to USB 3.0 Type A plug 02 = Receptacle connector to USB 3.0 Type A receptacle 03 = Receptacle connector to USB 3.0 Type B plug 04 = Receptacle connector to USB 3.0 Type μ B plug			
Overall Length	Length in Inches (12 inch minimum)			

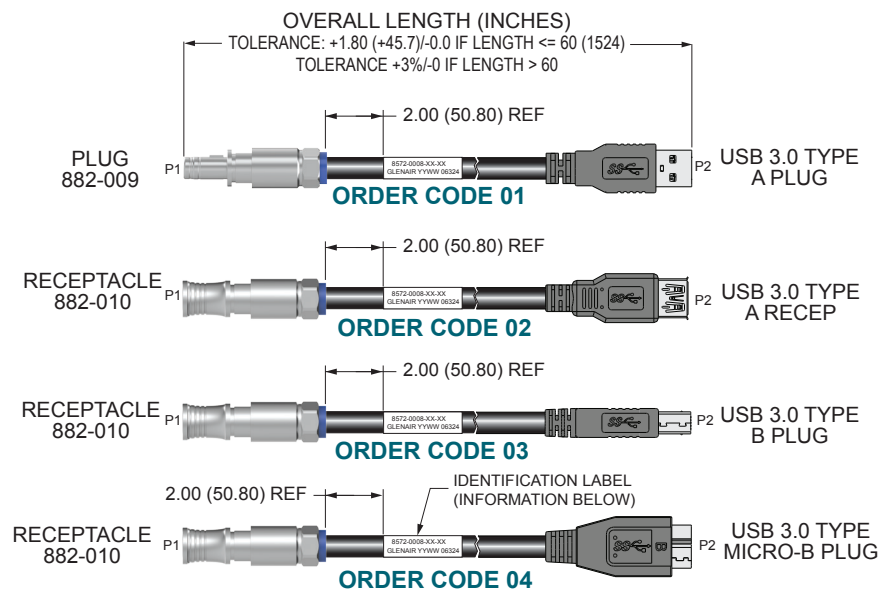

LABEL INFORMATION
 8572-0008-X-XX-XX
 GLENAIR YYWW 06324