

MIL-DTL-38999 Series I Type
 Quick selection guide

ENVIRONMENTAL CONNECTORS

QUICK SELECTION GUIDE		
Part Number	Description	Page
	Class G and NASA space-grade guidelines	A-5
231-206	Plug and receptacle connectors with integral banding porch	A-6
231-207	Wall-mount receptacles, flush flange	A-12
231-207-07	Jam-nut mount receptacle, flush flange	A-16
231-208	Wall-mount receptacle, stepped contacts	A-18
231-208-07	Jam-nut mount receptacle, stepped contacts	A-21
231-209	Wall-mount receptacle, washout standoffs	A-23
231-209-07	Jam-nut mount receptacle with standoffs	A-26
231-210	Wall-mount receptacle with standoffs	A-28
231-210-07	Jam-nut mount receptacle with standoffs	A-31
231-211	Dual-flange wall-mount receptacle	A-33
231-211-07	Jam-nut mount dual flange receptacle	A-37
231-212	Wall-mount feedthru receptacle connector	A-39
231-213	Sav-Con® connector saver, plug-to-receptacle interface	A-42
231-214	Sav-Con® connector saver, plug-to-plug interface	A-43
250-101	Shorting connectors, plug and receptacle	A-44




231-206



231-207-07



231-209-07

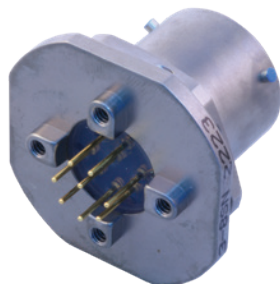

231-210-07



231-211-07



231-213