

MIL-DTL-38999 Series I Type Quick selection guide

QUICK SELECTION GUIDE		
Part number	Description	Page
	MIL-DTL-38999 Hermetic class insert arrangements	C-2
	MIL-DTL-38999 Hermetic class layouts and pin counts	C-4
	MIL-DTL-38999 Hermetic class material specifications and finishes	C-5
	MIL-DTL-38999 Connector performance specifications	C-6
	MIL-DTL-38999 Contact performance specifications	C-9
	MIL-DTL-38999 Alternate keyway positions	C-10
	Recommended torque values	C-11
	MIL-DTL-38999 Hermetic connectors and environmental mates	C-12
MS27469 / 231-100-H0	Wall-mount hermetic receptacle	C-13
MS27471 / 231-100-H5	Solder-mount hermetic receptacle	C-15
MS27470 / 231-100-H7	Jam-nut mount hermetic receptacle	C-17
231-100-H0	Wall-mount hermetic receptacle	C-19
231-100-H5	Solder-mount hermetic receptacle	C-21
231-100-H7	Jam-nut mount hermetic receptacle	C-22
231-106	Connector with crimp-removable socket contacts	C-24
231-250	Code red lightweight hermetic receptacle	C-28

HERMETIC CONNECTORS



MS27469 / 231-100-H0




MS27471 / 231-100-H5



MS27470 / 231-100-H7



231-100-H0

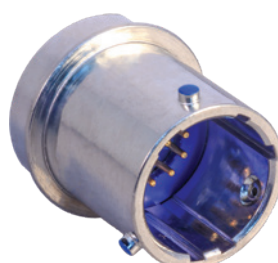

231-100-H5



231-250