
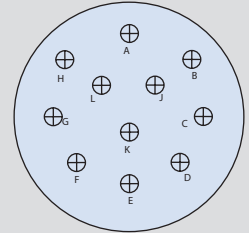
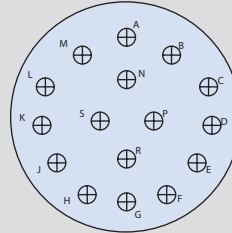
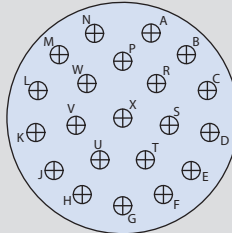


## MIL-DTL-38999 Series III Type

## MIL-STD-1560 Special shielded contact arrangements




HERMETIC CONNECTORS

**Contact Legend**  
 #22D • #16 ⊕  
 #20 ⊖ #12 ⊙  
 #8 ⊚

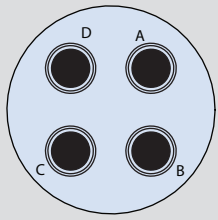




Insert Arrangement	21-75 and 21-76	23-21	23-97	23-99
Contact Size	#8	#16	#16	#16
No. of Contacts	4	21	16	11
Service Rating	Twinax	Coax	Coax	Coax

**Contact Legend**  
 #22D • #16 ⊕  
 #20 ⊖ #12 ⊙  
 #8 ⊚

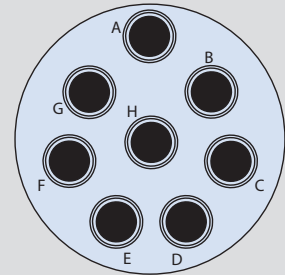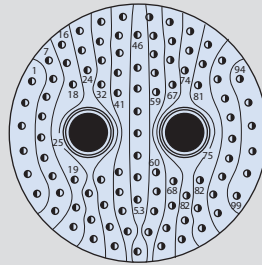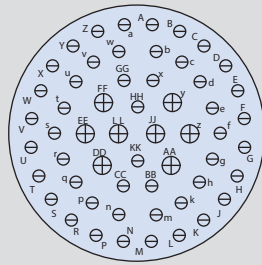

Insert Arrangement	25-4		25-7 and 25-9		25-8 and 25-10
Contact Size	#16	#20	#8	#22D	#8
No. of Contacts	8	48	2	97	8
Service Rating	Coax	I	Twinax	M	Twinax

**Contact Legend**  
 #22D • #16 ⊕  
 #20 ⊖ #12 ⊙  
 #8 ⊚

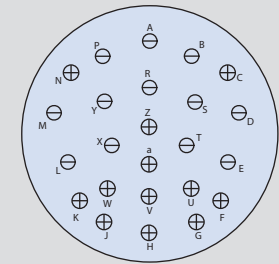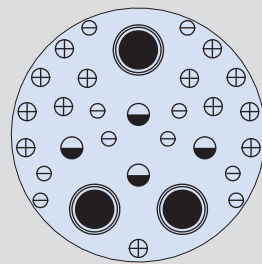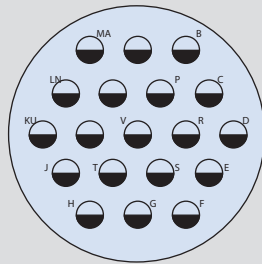

Insert Arrangement	25-19	25-20 and 25-21				25-24	
Contact Size	#12	#8	#12	#16	#20	#12	#16
No. of Contacts	19	3	4	13	10	12	12
Service Rating	Coax	Twinax	Coax	N		I	Coax




## MIL-DTL-38999 Series III Type

## MIL-STD-1560 Special shielded contact arrangements

HERMETIC CONNECTORS

Contact Legend



- #22D • #16 ⊕
- #20 ⊖ #12 ⊙
- #8 ⊚

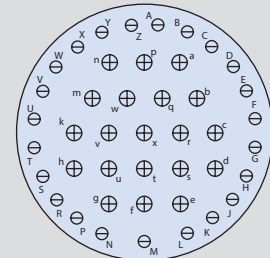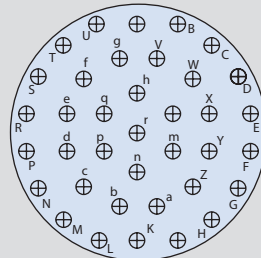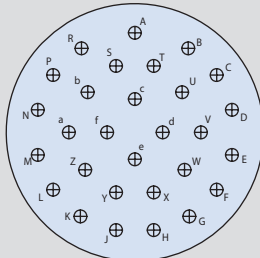

Insert Arrangement	25-29		25-37		25-43	
Contact Size	#16		#16		#16	#20
No. of Contacts	29		37		20	23
Service Rating	Coax		Coax		Coax	I

Contact Legend

- #22D • #16 ⊕
- #20 ⊖ #12 ⊙
- #8 ⊚

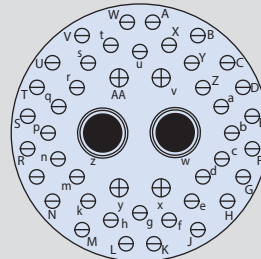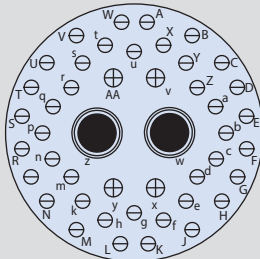

Insert Arrangement	25-46 and 25-47			25-90 and 25-91		
Contact Size	#8	#16	#20	#8	#16	#20
No. of Contacts	2	4	40	2	4	40
Service Rating	Coax	I		Twinax	I	