



RJ45 AND USB 2.0


Contacts, Tools, and Accessories



310-001 Shrink Boot Adapter with Rotatable Coupling for 28840 Type Connectors



How To Order						
Sample Part Number	310	G	S	001	M	17
Series/Basic Part No.	310 - Shrink Boot Adapter					
Connector Designator	G = 28840					
Angular Function	S = Straight For 45° and 90° versions contact factory					
Basic Part No.	001					
Finish	See Material and Finish Table					
Shell Size	15, 17, 19					

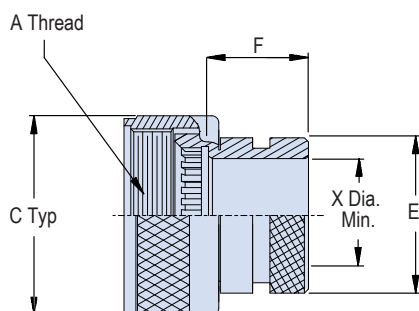

Materials and Finishes	
NF	Aluminum/ Cadmium olive drab
M	Aluminum/ Electroless nickel
MT	Aluminum/ Nickel PTFE
ZR	Aluminum/ Zinc-nickel black
Z1	Stainless Steel/ Passivate

Dimensions					
Shell Size	A Thread	C Typ	E Max	F Max	X Dia. Min.
15	M22 X 1 -- 6H	1.07 (27.2)	.838 (21.3)	.940 (23.9)	.565 (14.4)
17	M25 X 1 -- 6H	1.21 (30.7)	.963 (24.5)	.940 (23.9)	.690 (17.5)
19	M28 X 1 -- 6H	1.36 (34.5)	1.042 (26.5)	.940 (23.9)	.769 (19.5)

Recommended Shrink Boot*		
Shell Size	Shrink Boot with Low Temp Adhesive	Shrink Boot without Low Temp Adhesive
15	770-028S904 Lipless boot	770-028S904U Lipless boot
17	770-028S906	770-028S906U
19	770-028S906	770-028S906U

* Shrink Boot **MUST** be ordered seperately.

Shrink boot material: compound 2013 low temperature polyolefin.