




RJ45 AND USB 2.0 Contacts, Tools, and Accessories




Series IPT Protective Covers for Wall Mount and Jam Nut Receptacle Connectors

How To Order				
Sample Part Number	IPT3181 -18 CF F6			
Series/Basic Part No.	IPT3181 = Receptacle Cover (See Note 1)			
Connector Size	16 = Shell Size 16 18 = Shell Size 18			
Lanyard Style	Wall Mount C = Sash Chain CF = Nylon Cord Z1C = Nylon Cord with Loose Terminal and Sleeve Jam Nut Mount N = Sash Chain NF = Nylon Cord			
Finish Options	F6 = Aluminum/Black Polymer Electrocoat F11 = Aluminum/Electroless Nickel F7 = Aluminum/Conductive Black Zinc Nickel Omit for Aluminum/Cadmium, Olive Drab			


IPT WALL MOUNT RECEPTACLE COVER

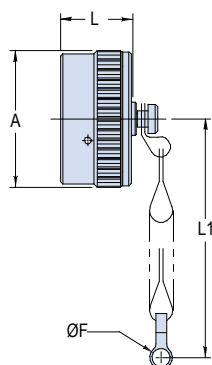


Example: IPT3181-18C
(Stainless Steel Sash Chain)

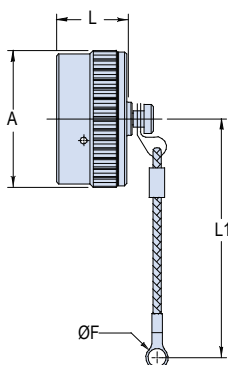


Example: IPT3181-18CF
(Nylon Cord)

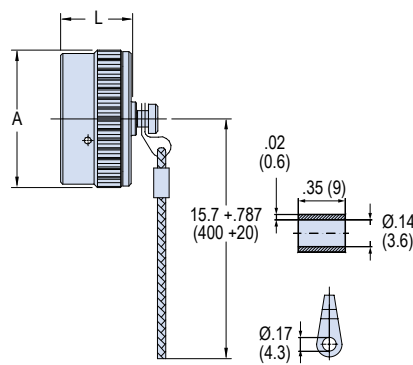


Example: IPT3181-18Z1C
(Nylon Cord with loose terminal and sleeve)

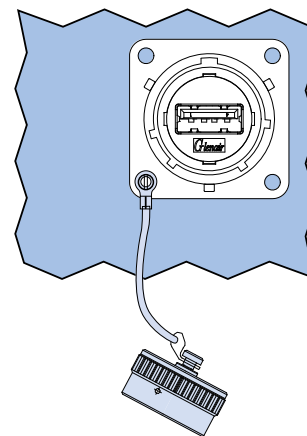


IPT JAM NUT MOUNT RECEPTACLE COVER

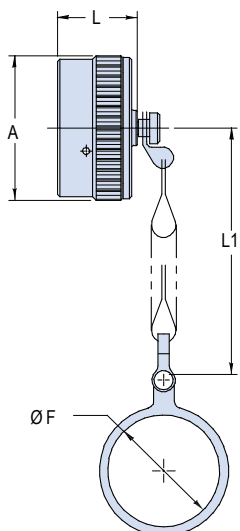

Example: IPT3181-18N
(Stainless Steel Sash Chain)

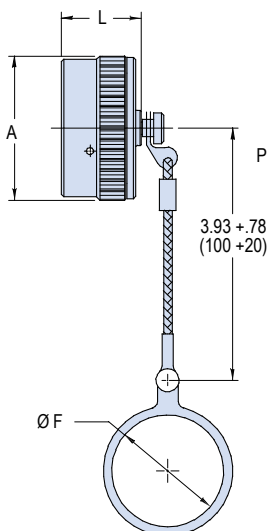

Example: IPT3181-18NF
(Nylon Cord)

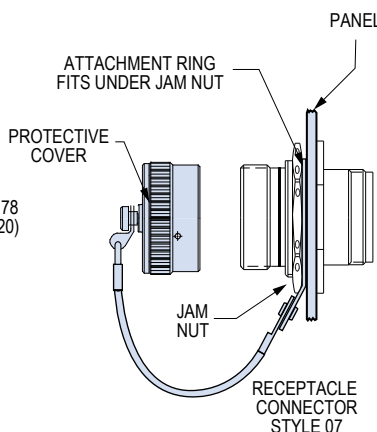

Dimensions for Wall Mount and Jam Nut Covers				
Shell Size	A Max.	ØF +.874 (+0.2) -.004 (-0.1)	L +.197 (+0.5) -0 (-0)	L1 Min.
16	1.256 (31.90)	.169 (4.3)	.563 (14.30)	3.5 (88.9)
18	1.378 (35.00)	.169 (4.3)	.563 (14.30)	3.5 (88.9)

NOTES

- For plug covers contact factory