



USB 2.0 TYPE A

Series ITS (5015 type) Reverse-Bayonet




ITS370 Feedthrough Receptacle with USB Female-to-Female Interface




		How to Order							
Sample Part Number		ITS370	03PP	16	2	A	A	H	F6
Basic Number		ITS370							
Connector Style ¹		03PP = Rear panel mount receptacle bulkhead feed through							
Shell Size		16							
USB Performance		2 = 2.0							
USB Front Interface Type		A = Type A							
USB Rear Interface Type		A = Type A							
USB Orientation		H = Horizontal V = Vertical							
Material/Finish		Omit for Al/Cadmium, Olive Drab (G3) F6 = Black Polymer Electrocoat F7 = Conductive Black Zinc Nickel F11 = Electroless Nickel							

Recommended Panel Cutout

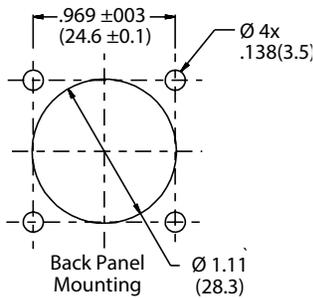



USB RECEPTACLE ORIENTATION OPTIONS

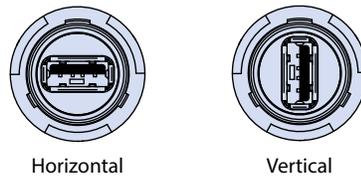

NOTES

- See Section A for panel cutout dimensions

Square Flange Mount Recommended Mounting Holes Panel Thickness .315 (8) Max

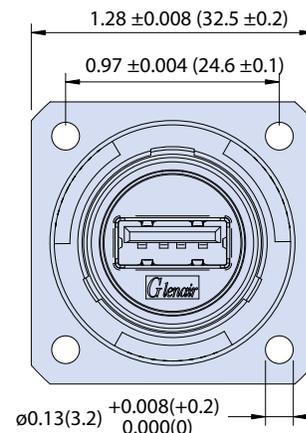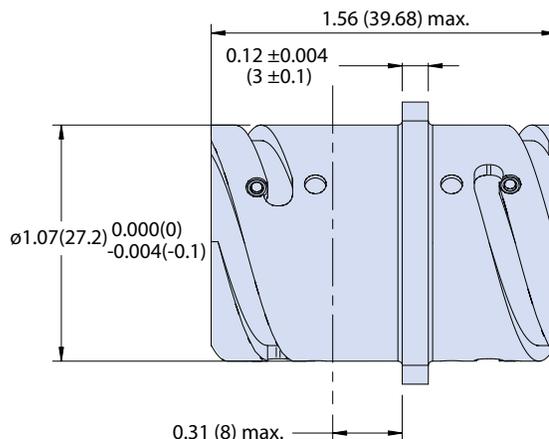

E