



MICRO USB 2.0 Series 805 Mighty Mouse



805-089 and 805-090 Receptacle Adapter with USB Micro "AB" Female-to-Female Interface


Series 805 Triple Start




Receptacles and Rear View of Micro-AB Female Interface

How To Order				
Sample Part Number	805-089	-02 MUSB	-M	A
Series	805-089 = Shield Termination Porch 805-090 = Accessory Threads			
Shell Style	01 = In-line Receptacle 02 = Square Flange Mount Receptacle 07 = Jam Nut Mount Receptacle			
Shell Material and Finish ¹	NF = AL/Cadmium, Olive Drab MT = AL/Nickel PTFE		M = AL/Electroless Nickel ZNU = AL/Black Zinc Nickel	
Alternate Key Positions ¹	A, B, C, D, E, F			


805-089 AND 805-090 IN-LINE RECEPTACLE, SHELL SIZE 10^{1,2}

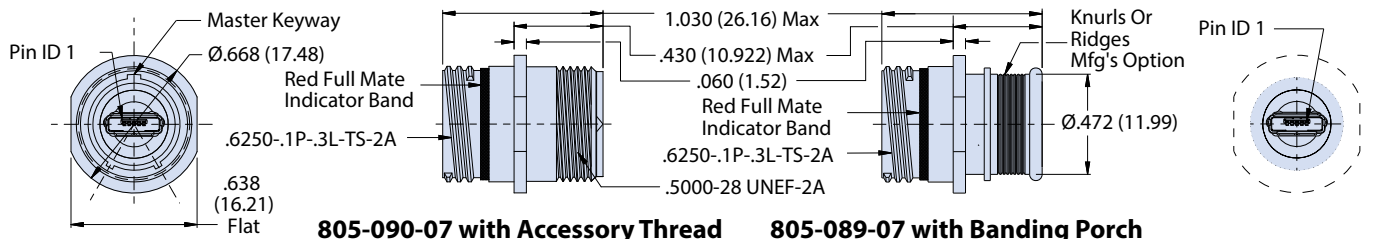

805-089 AND 805-090 SQUARE FLANGE RECEPTACLE, SHELL SIZE 10^{1,2}

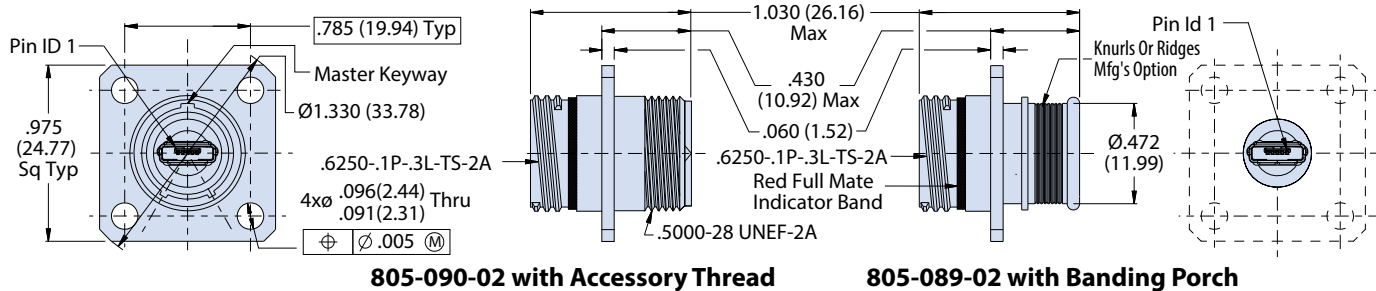

805-089 AND 805-090 JAM NUT RECEPTACLE, SHELL SIZE 10^{1,2}

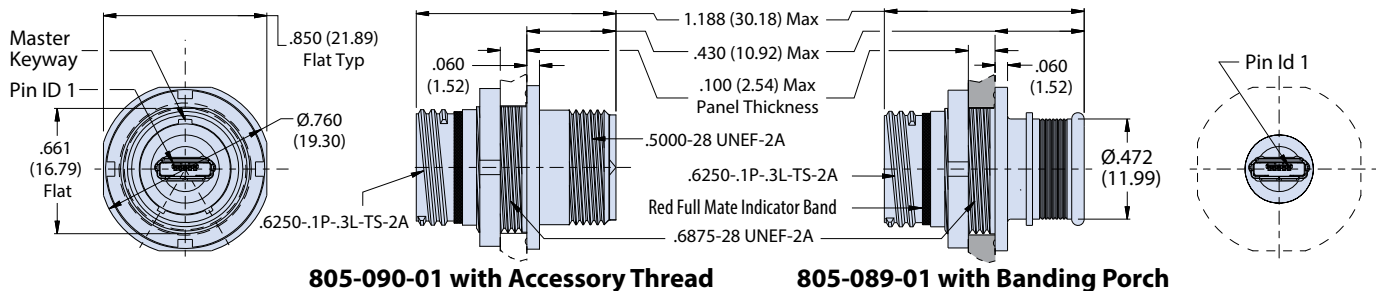

NOTES

- See Section A for recommended panel cutout, finishes and alternate keyway positions.
- These plug connectors mate with Glenair receptacles 805-082, 805-083, 805-087 and 805-088.

Micro "AB" accepts both Micro "A" and "B" male interfaces.

