



RJ45 CAT 5E ETHERNET

MIL-DTL-38999 Series III Type Connectors



CAT 5e cable assemblies


2330-0003 Glenair SuperNine RJ45 CAT 5e cable jumpers, SuperSeal to standard RJ45

SuperSeal RJ45 connectors are IP67 open face rated and IP68 in the mated condition for complete protection in harsh environments. SuperSeal connector styles include plug, wall mount and jam-nut receptacles. Wall mount receptacles are available with slotted holes, round holes and metric clinch nuts. All SuperSeal shells offer inline shielding and receptacle shells offer optional shell grounding. Any shell can be ordered with straight or right angle cable exit. RJ45 jack can be ordered in 1 of 4 available orientations to provide further security against mis-mating and accommodate existing RJ45 orientations. RJ45 connector end may be ordered as plug, jack or with flying leads in straight or right angle configurations. Maximum overall length is 100 feet. Consult factory for ordering information.

AVAILABLE INTERFACE OPTIONS




Plug

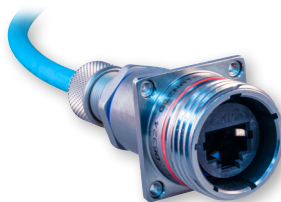


Wall mount
receptacle with
metric clinch nuts



Wall Mount
Receptacle with
round holes

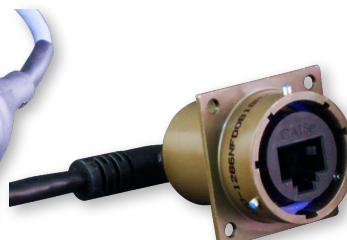

Wall Mount
Receptacle with
round holes

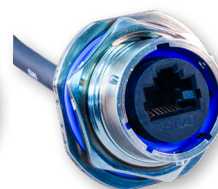

Jam-nut mount
Receptacle

CAT 5E PLUG OPTIONS



CAT 5e, Straight




CAT 5e, 45°


RJ45 ORIENTATION OPTIONS




Master Keyway

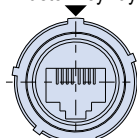


Code 1

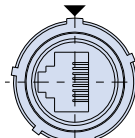

Code 2

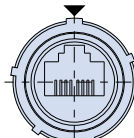

Code 3

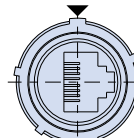

Code 4