




RJ45 CAT 5E ETHERNET COMPATIBLE Series 801, 804 and 805 Mighty Mouse 805-302 Triple-Start Receptacle with RJ45 Jack to PC Tail Termination



How To Order								
Sample Part Number	805-302	NF	07	G	19	5H	A	1
Series	805-302 = PC Tail							
Material and Finish ¹	NF = Aluminum/Cadmium, Olive Drab M = Aluminum/Electroless Nickel MT = Aluminum/Nickel PTFE ZNU = Aluminum/Black Zinc Nickel							
Shell Style ¹	02 = Front or Rear Panel Mount Square Flange Receptacle 12 = Rear Panel Mount Square Flange Receptacle with "Non-Locking" Clinch Nuts 22 = Rear Panel Mount Square Flange Receptacle with "Locking" Clinch Nuts 07 = Rear Panel Mount Jam Nut Receptacle							
Grounding	G = Shielded and grounded to shell For improved 360° shielding performance select shell size 21							
Shell Size	19 = Shell Size 19 21 = Shell Size 21							
RJ45 Category	5H = Cat 5E For Cat 6A applications consult factory							
Alternate Key Positions ¹	A, B, C, D, E, F ; A = Normal							
RJ45 Orientation Option	1, 2, 3, 4							

RJ45 RECEPTACLE ORIENTATION OPTIONS AND PCB FOOTPRINT (PARTIAL VIEWS SHOWN)

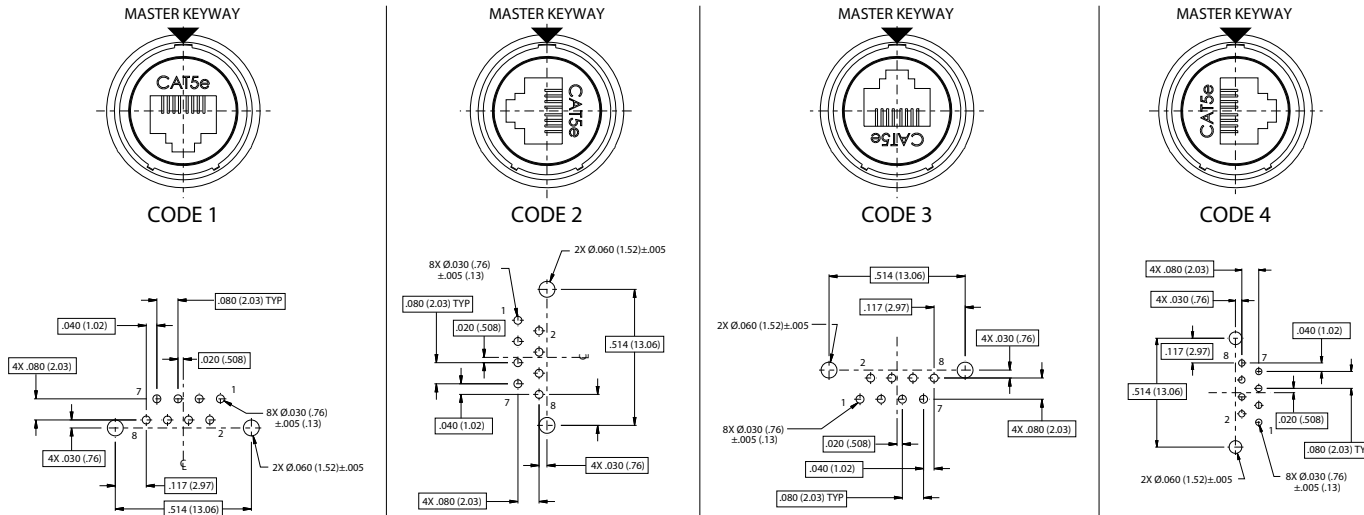

Square Flange Mount Dimensions									
Shell Size	Ø A	B Flat	C Thread	Ø D	Ø E	F SQ	G BSC	Ø H	J SQ
19	1.235 (31.69)	1.205 (30.61)	1.1875-1P-3L-TS-2A	0.912 (23.16)	2.094 (53.19)	1.537 (39.04)	1.327 (33.71)	2.197 (55.80)	1.647 (41.83)
21	1.360 (34.54)	1.330 (33.78)	1.3125-1P-3L-TS-2A	1.017 (25.83)	2.270 (57.66)	1.663 (42.24)	1.452 (36.88)	2.380 (60.45)	1.772 (45.01)

Jam Nut and Plug Dimensions				
Shell Size	Ø K	L	M Flat	N Thread
19	1.450 (36.83)	1.420 (36.07)	1.221 (31.01)	1.2500-28 UN-2A
21	1.590 (40.39)	1.560 (39.62)	1.350 (34.29)	1.3750-28 UN-2A

NOTES

1. See Section A for recommended panel cutout dimensions, additional finishes and alternate keyway positions
2. Meets IP67 sealing requirement in unmated condition




RJ45 CAT 5E ETHERNET COMPATIBLE Series 801, 804 and 805 Mighty Mouse 805-302 Triple-Start Receptacle with RJ45 Jack to PC Tail Termination




SHELL STYLE 01 INLINE

RJ45 Jack Category (Cat 5e) Orientation 3 Shown

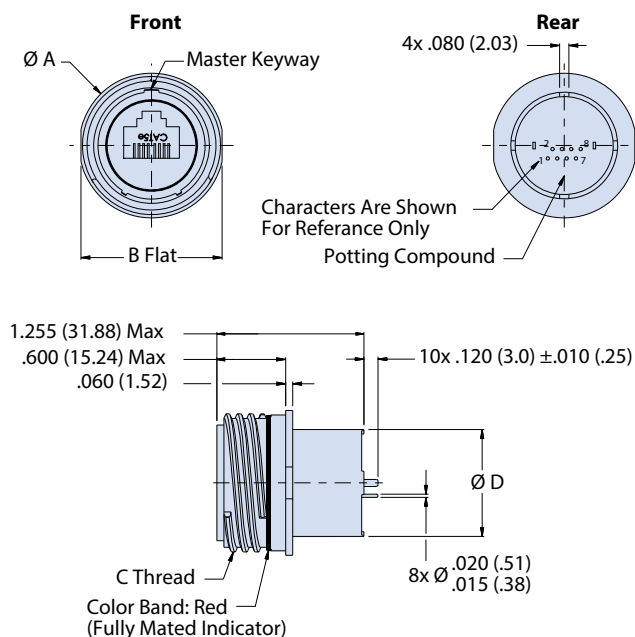


SHELL STYLE 07 JAM NUT

RJ45 Jack Category (Cat 5e) Orientation 3 Shown

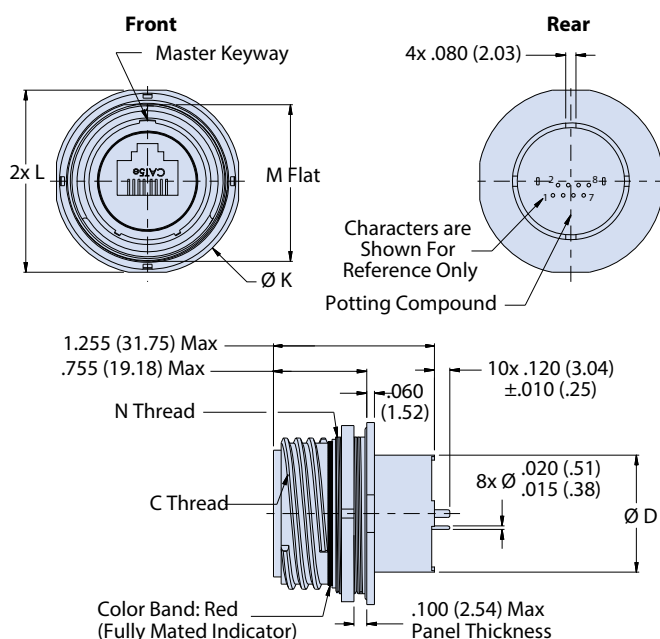

SHELL STYLE 02 FRONT OR REAR PANEL MOUNT SQUARE FLANGE RECEPTACLE

RJ45 Jack Category (Cat 5e) Orientation 3 Shown

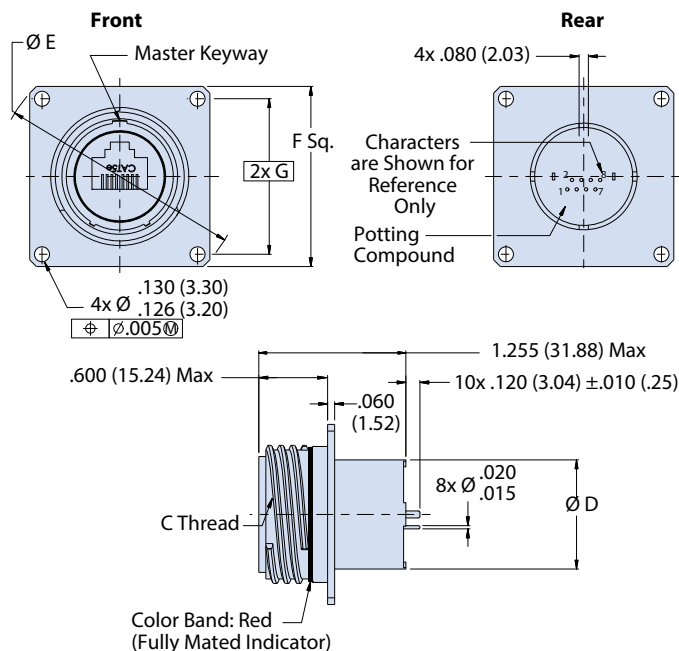

SHELL STYLE 12 AND 22 REAR PANEL MOUNT SQ FLANGE RECEPTACLE WITH CLINCH NUTS

RJ45 Jack Category (CAT 5e) Orientation 3 Shown

