




RJ45 CAT 5E ETHERNET COMPATIBLE  
**Series 801, 804 and 805 Mighty Mouse**  
 805-303 Triple-Start Receptacle with  
 RJ45 Jack to Solder Cup Termination



Series 805 Triple Start

How To Order	
<b>Sample Part Number</b>	<b>805-303 NF 07 G 19 5H A 1</b>
<b>Series</b>	<b>805-303</b> = Solder Cup
<b>Material and Finish<sup>1</sup></b>	<b>NF</b> = Aluminum/Cadmium, Olive Drab <b>M</b> = Aluminum/Electroless Nickel <b>MT</b> = Aluminum/Nickel PTFE <b>ZNU</b> = Aluminum/Black Zinc Nickel
<b>Shell Style<sup>1</sup></b>	<b>02</b> = Front or Rear Panel Mount Square Flange Receptacle <b>12</b> = Rear Panel Mount Square Flange Receptacle with "Non-Locking" Clinch Nuts <b>22</b> = Rear Panel Mount Square Flange Receptacle with "Locking" Clinch Nuts <b>07</b> = Rear Panel Mount Jam Nut Receptacle
<b>Grounding</b>	<b>G</b> = Shielded and grounded to shell For improved 360° shielding performance select shell size 21
<b>Shell Size</b>	<b>19</b> = Shell Size 19 <b>21</b> = Shell Size 21
<b>RJ45 Category</b>	<b>5H</b> = Cat 5E                      For Cat 6A applications consult factory
<b>Alternate Key Positions<sup>1</sup></b>	<b>A, B, C, D, E, F</b> ; A = Normal
<b>RJ45 Orientation Option</b>	<b>1, 2, 3, 4</b>

**RJ45 RECEPTACLE ORIENTATION OPTIONS (PARTIAL VIEWS SHOWN)**

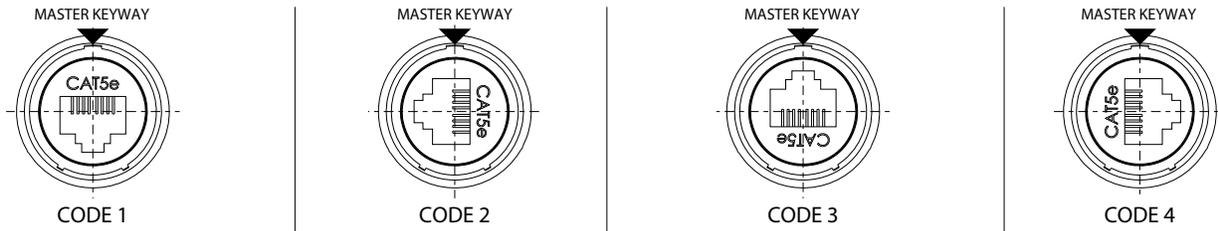

Square Flange Mount Dimensions									
Shell Size	Ø A	B Flat	C Thread	Ø D	Ø E	F SQ	G BSC	Ø H	J SQ
19	1.235 (31.69)	1.205 (30.61)	1.1875-.1P-.3L-TS-2A	.912 (23.16)	2.094 (53.19)	1.537 (39.04)	1.327 (33.71)	2.197 (55.80)	1.647 (41.83)
21	1.360 (34.54)	1.330 (33.78)	1.3125-.1P-.3L-TS-2A	1.017 (25.83)	2.270 (57.66)	1.663 (42.24)	1.452 (36.88)	2.380 (60.45)	1.772 (45.01)

Jam Nut and Plug Dimensions				
Shell Size	Ø K	L	M Flat	N Thread
19	1.450 (36.83)	1.420 (36.07)	1.221 (31.01)	1.2500-28 UN-2A
21	1.590 (40.39)	1.560 (39.62)	1.350 (34.29)	1.3750-28 UN-2A

**NOTES**

- See Section A for recommended panel cutout dimensions, additional finishes and alternate keyway positions
- Meets IP67 sealing requirement in unmated condition
- Materials/Finishes:
  - Insulators: high grade rigid dielectric/n.a.
  - contacts: copper alloy, gold plated
  - seals: silicone based elastomer
  - RJ45 coupler housing: UL94V-0 compliant ABS or PPS
  - hardware: stainless steel/passivated




RJ45 CAT 5E ETHERNET COMPATIBLE  
**Series 801, 804 and 805 Mighty Mouse**  
 805-303 Triple-Start Receptacle with  
 RJ45 Jack to Solder Cup Termination




Series 805 Triple Start

K


**SHELL STYLE 01 INLINE**

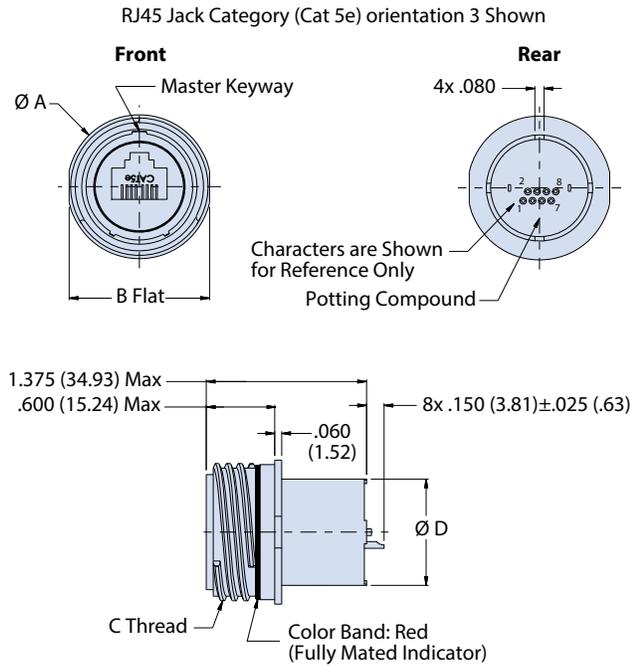

**SHELL STYLE 07 JAM NUT**

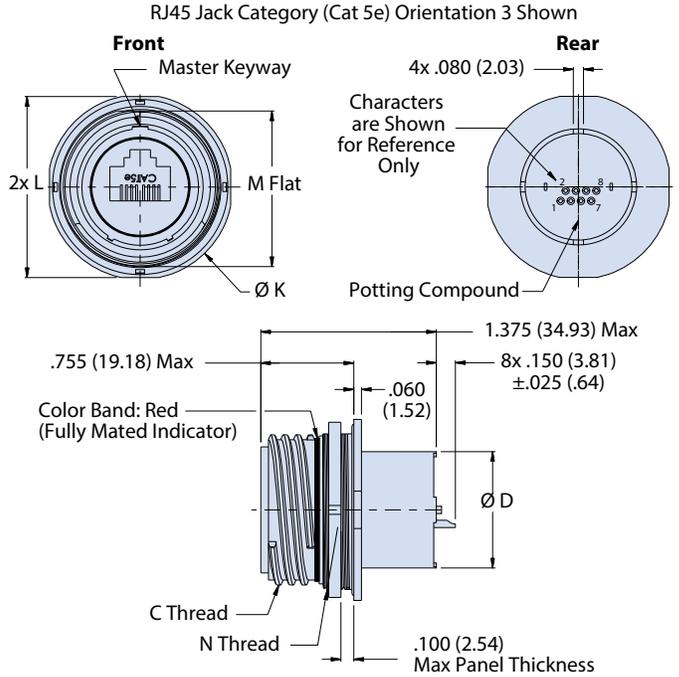

**SHELL STYLE 02 FRONT OR REAR PANEL MOUNT SQUARE FLANGE RECEPTACLE**

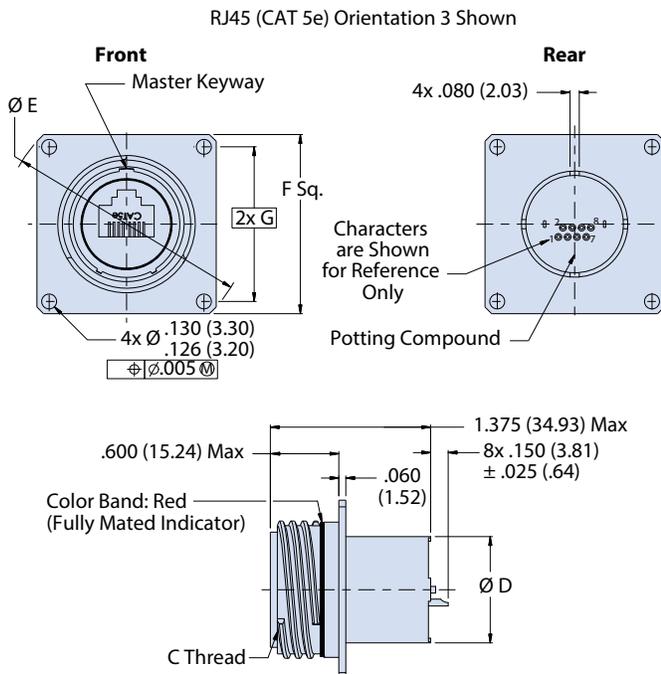

**SHELL STYLE 12 AND 22 REAR PANEL MOUNT SQ FLANGE RECEPTACLE WITH CLINCH NUTS**

