
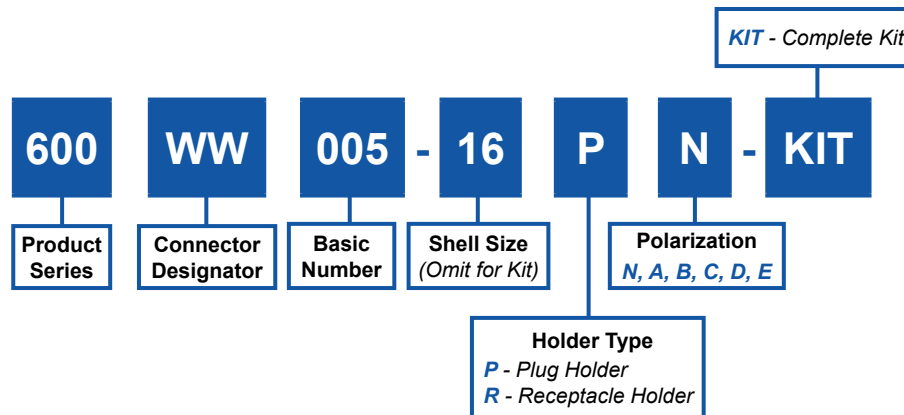


**600WW005**  
**Glenair Series 22 Connectors**  
**Plug and Receptacle Holder**

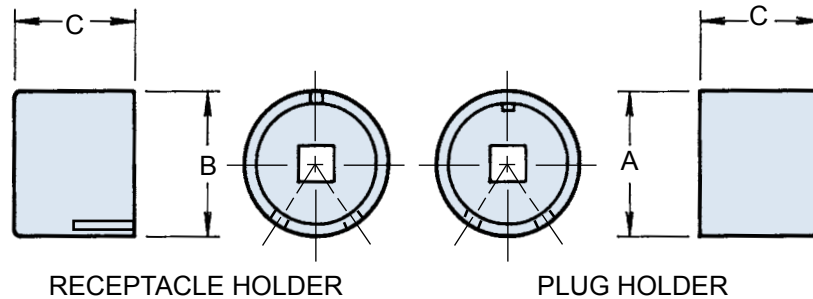

| Shell Size | Max. Recommended Torque (Inch Pounds) | A Dia. Max.  | B Dia. Max.  | C Dim. Max. |
|------------|---------------------------------------|--------------|--------------|-------------|
| 10         | 40                                    | .705 (17.9)  | .496 (12.6)  | 1.03 (26.2) |
| 12         | 40                                    | .830 (21.1)  | .620 (15.7)  | 1.03 (26.2) |
| 14         | 50                                    | .955 (24.3)  | .750 (19.1)  | 1.03 (26.2) |
| 16         | 50                                    | 1.070 (27.2) | .870 (22.1)  | 1.03 (26.2) |
| 18         | 60                                    | 1.195 (30.4) | .995 (25.3)  | 1.03 (26.2) |
| 20         | 70                                    | 1.320 (33.5) | 1.120 (28.4) | 1.03 (26.2) |
| 22         | 80                                    | 1.445 (36.7) | 1.245 (31.6) | 1.03 (26.2) |
| 24         | 100                                   | 1.570 (39.9) | 1.370 (34.8) | 1.03 (26.2) |

**APPLICATION NOTES**

1. Metric dimensions (mm) are indicated in parentheses.
2. Material: Case hardened carbon steel with electroless nickel finish.
3. Receptacle and plug holder drives: 1/4" - Shell sizes 10 and 12; 3/8" - Shell sizes 14 and up.